

LED Warehouse/Industrial Lighting

High Ambient Temperature LED UFO Luminaire

Features


- Suitable for high temperature applications
- Built-in cooling fins provide maximum heat dissipation
- Die cast hook mount standard for ease of installation
- Heat & impact resistant polycarbonate lens
- Motion sensor version (HTS version)
- UL certified per NSF/ANSI Standard 2 - Food Equipment for use in Splash Zone Applications
- 0-10 Dimming*

Specs


- 127 Lumens Per Watt (LPW)
- 70 CRI
- 120° Beam Angle
- 50,000 Average Rated Life
- -40°F to 145°F ambient rating

Applications

- Warehouses, gymnasiums, industrial lighting

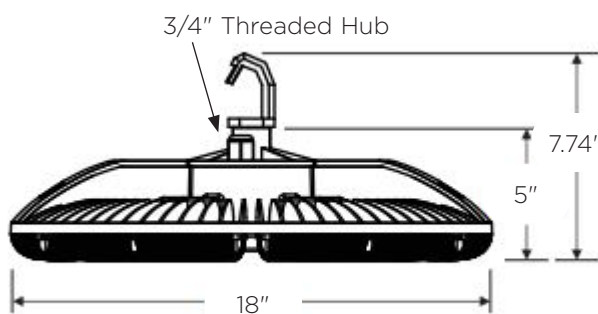

Optional Wire
Safety Guard

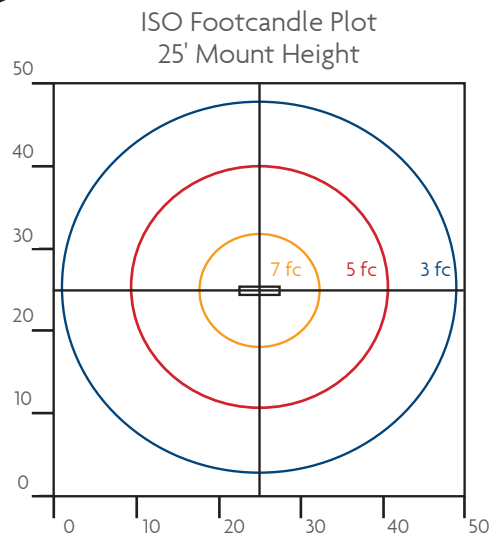

Catalog Number	Product Code	Color Temp	Watts	Volts	Lumens	Equiv Wattage	Case Qty	DLC ID
F-LUHB150/50/HT	74132	5000K	150	120-277	19,113	Up to 400W HID	1	P2QNVGUA
F-LUHB150/50/HT/480	74137	5000K	150	480	19,113	Up to 400W HID	1	PXFSSPKC
F-LUHB150/50/HTS	74138	5000K	150	120-277	19,113	Up to 400W HID	1	P2QNVGUA

Optional 10-PK Wire Safety Guard

F-LUHB/HT-Guard 74150 (UPC:751338018525)

Specifications are subject to change without prior notice. *Dimming with standard 0-10V dimmer, such as Leviton, IP710, DS710 or Lutron DVSTV.