




PRODUCT SPECIFICATION

PRODUCT:	07145 Cord-O-Lite™
DESCRIPTION:	Temporary lighting string, with molded lampholders attached to 14/2 SJTW flexible cord. An attachment plug cap is provided.
APPLICATIONS:	Temporary indoor and outdoor illumination in accordance with the NEC
APPROVALS:	UL Listed; meets OSHA and NEC requirements.

CONSTRUCTION PARAMETERS:

Conductor:	14 AWG, 41/30 stranding, bare copper
Cable insulation and jacket material:	PVC
Cable jacket color:	Yellow

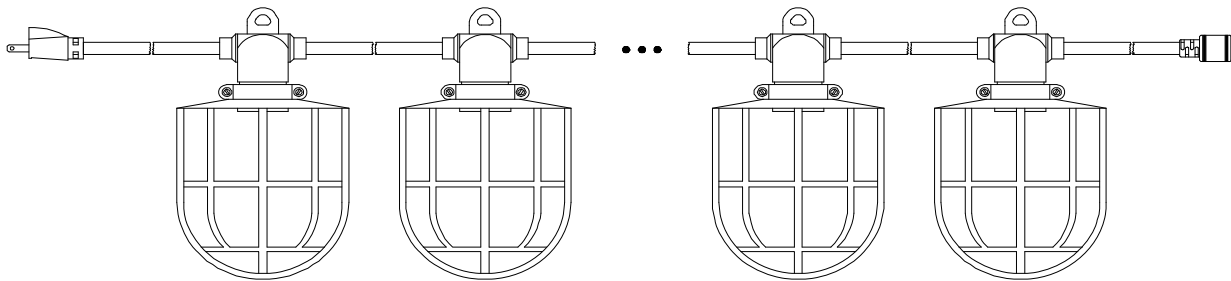

Note: Plug style may vary.

Cable length:	100 ft.
Number of lampholders:	10
Lampholder spacing (nom):	10 feet, starting 9 ft from the plug
Lampholder molding compound:	High temperature PVC, black
Plug configuration:	NEMA 1-15P, polarized
Plug material:	PVC
Plug color:	Black

ELECTRICAL PROPERTIES:

Cable temperature rating:	-40 to +60° C
Nominal operating voltage:	125 VAC
Lamp type:	150 W (max), A-23 or larger

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Inc. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Inc.