




RIGID-IMC FITTINGS

ALUMINUM THREADED CONDUIT BODIES WITH COVER AND GASKET

[Download
Specification Sheet
\(\[https://www.sepco-usa.com/wp-content/uploads/2017/03/page_047.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page_047.pdf\)\)](#)



[Print](#)

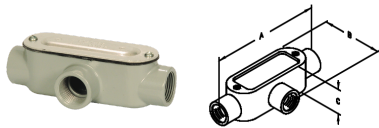

T1ACG

Trade Size	1/2"
Dim A	4.75
Dim B	2.06
Dim C	1.38
MAX WIRE SIZE	N/A
VOL. CU.IN.	4.35
Unit Pack	10
Master Pack	50
Lbs. / 100 Pcs.	23
UPC	10069
	T-50ACGA,
	T-41CG,
	58805,
Competitor Part	T50CG,
Number	LTLA-50, T-

APPLICATION FEATURES

To provide access to conductors for pulling, splicing, and maintenance.	Tapered threaded hubs (NPT) Assembled with neoprene gasket and stamped cover
Threaded for rigid conduit and IMC	Die cast from high-strength, corrosion and weather resistant, copper-free aluminum alloy.
	Flat back design for easy mounting close to walls

STANDARD MATERIALS	STANDARD FINISH
---------------------------	------------------------

1/2" – 2"	Aluminum
Die cast/Copper-free Aluminum	Enameled
2-1/2" – 4"	
Sand-	

cast/Copper-
free
Aluminum

UL LISTED

E198259