



Ocal®

Conduit Fittings-PVC Coated T&B Catalog Number:

UPC Number: STG3-G
70450840886
Status: Active
Description:

PVC Coated Zinc Grounded Hub with Thermoplastic Insulated Throat, Pipe Size 1 Inch/27 Metric, Overall Diameter 2.00 Inch/50.80 Millimeters, Maximum Panel Thickness 0.25 Inch/6.35 Millimeters, Throat Diameter 1.00 Inch/25.40 Millimeters, Nitrile Rubber (Buna-N) Sealing Ring, Dark Gray

Features

- Coated with a nominal .002 in. (2 mil) blue urethane on the interior, before PVC Coating is applied.
- A minimum .040 in. (40 mil) PVC Coating is bonded to the exterior.
- Innovative sealing ring and groove.
- Hexagonal body and locknut design.
- Insulated throat and sharper and deeper teeth.
- Pressure sealing sleeves to protect the connection.

General

Custom_Finish	stg_1
Trade Size (inches)	1
Material	Zinc
Finish	PVC Coated
Color	Dark Gray

Dimension Information

Dimension A (inches)	2
Dimension B (inches)	1 13/16
Dimension C (inches)	1 1/16
Dimension D (inches)	1/4
Dimension E (inches)	1

Technical Information


Chemical Resistance Chart	Available on Website
---------------------------	----------------------

Specifications

Ocal Specification Guide-1995 Master Format-PDF	Available on Website
Ocal Specification Guide-1995 Master Format-DOC	Available on Website
Ocal Specification Guide-2004 Master Format-PDF	Available on Website
Ocal Specification Guide-2004 Master Format-DOC	Available on Website

Packaging

Package in Units	40
T&B Sold in UOM	Each
T&B Weight Per UOM	0.5 lbs. Each

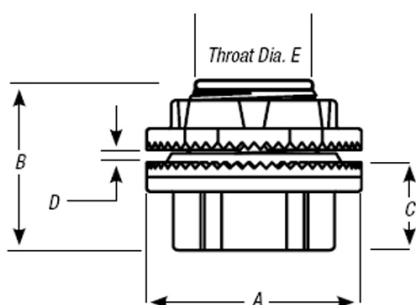

Application Support

Ocal Specifications	Available on Website
Recommended Installation Procedures	Available on Website
Product Overview-Conduit Outlet Bodies	Available on Website
NEMA Standards-RN 1	Available on Website
NEC 310-16 - Conductors for General Wiring	Available on Website
NEC Table 8	Available on Website

Notes

Dimensional values are of uncoated fittings.

Standard color is dark gray. Also available in white and light blue. Custom colors are also available upon request. Please contact Technical Services, 888-862-3289.

Certifications

RoHS Compliance	Yes
-----------------	-----

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com