

OVERVIEW

The *SilverBullet* is a "sub-branch circuit current limiter" for track lighting that enforces a definite current limit to lower the VA rating of each track lighting circuit and meet code requirements.

FEATURES

- Current limiting for up to 21 circuits
- Current limiting breakers available from 1A-15A
- Compact sizes 12" W X 18" H X 4" D or 12" W X 12" H X 4" D
- AIC rating of 10,000A @ 120V - 277V
- Factory pre-assembled with each load factory labeled on the door sheet

SPECIFICATIONS

Enclosure dimensions:	1-12 breakers
	12"W x 12"H x 4"D
	6-21 breakers
	12"W x 18"H x 4"D
Enclosure type:	Surface mount, hinged locking door, NEMA 1
Optional enclosures:	Flush mount
Max. humidity:	10–90% non-condensing
Ambient temperature:	32–104° F (0–40° C)
	(Note: Thermal magnetic breakers. De-rate to 80% of load for temperatures over 70° F)
Listings:	UL listed

Warranty

Three-year limited warranty. Complete warranty terms located at:

www.acuitybrands.com/CustomerResources/Terms_and_conditions.aspx

Note: Actual performance may differ as a result of end-user environment and application.

Specifications subject to change without notice.

AcuityControls™


LC&D™

GR 2400™
The SilverBullet




ORDERING INFORMATION

SILVERBULLET				EXAMPLE: T24 1077UL 10BP 1A3 3A7 SM	
System		Breaker UL Listing	Breaker Postitions	Breaker	Enclosure Mountings
T24	Standard (21 breakers max.)	1077UL	Standard	[qty]BP # of positions	SM Surface Mount
T24M	Mini (12 breakers max.)			Where [qty] is, replace with the total number of breakers needed in a panel, within a range depending upon the specified panel: T24 is from six and 21 breakers, T24M is from one to 12.	FM Flush Mount
				1A[qty] 1 amp breaker	
				2A[qty] 2 amp breaker	
				3A[qty] 3 amp breaker	
				4A[qty] 4 amp breaker	
				5A[qty] 5 amp breaker	
				6A[qty] 6 amp breaker	
				7A[qty] 7 amp breaker	
				8A[qty] 8 amp breaker	
				10A[qty] 10 amp breaker	
				13A[qty] 13 amp breaker	
				15A[qty] 15 amp breaker	

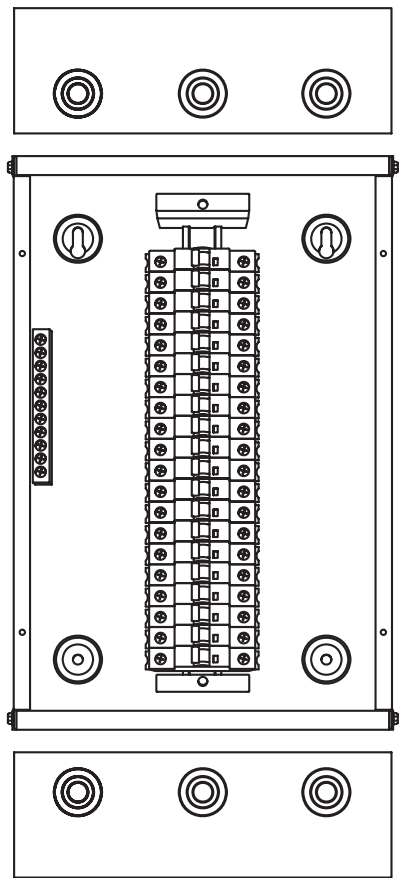

SUPPLEMENTAL CURRENT LIMITING PANEL
NEMA 1 ENCLOSURE WITH HINGED LOCKING DOOR
UP TO 21 CURRENT LIMITERS: 12"W X 18"H X 6"D

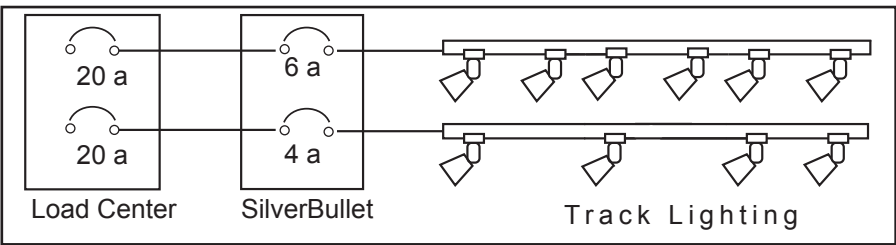

More Track-Less Penalty

The SilverBullet is UL listed to be placed in-line between the branch circuit breaker and the track mounted lighting loads.

When doing energy calculations, use the ampere rating of the supplementary breaker in the SilverBullet as opposed to the linear footage of the rack.