




Catalog Number: 6624-GHC1
Item Description: N1 HINGE CVR GUTTER
UPC Code: 784572107847

Brand Name: Milbank
Type: Lay In Wireway
Application: Wireway
Standard: UL Listed, Type 1
Cover Type: Hinge Cover
Enclosure: Indoor Enclosure
Nominal Cross Section: 6x6
Straight Section Length: 24
Material: Steel with Powder Coat Finish
Finish: ANSI 61 Gray
Knockouts: True



Utility requirements may vary. Always consult the serving utility for their requirements prior to ordering or installing this equipment. This product must always be installed by a licensed electrician. Installation of this equipment may require local electrical inspector approval.


CATALOG#	LABEL#
6624-GHC1-()	1002943
RC-6624-GHC1-()	1125051
SPH-662()	1132575

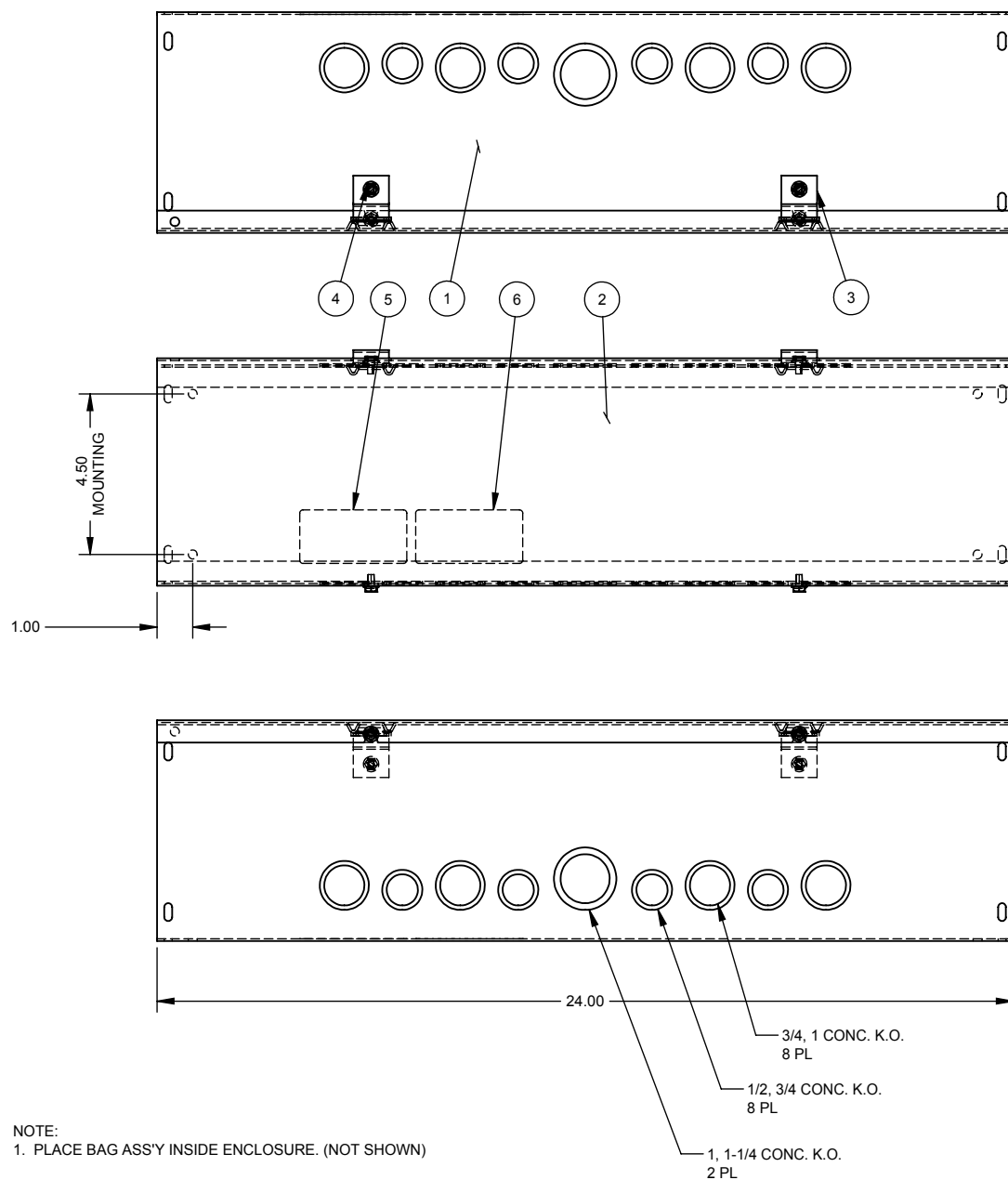

NOTE:
1. PLACE BAG ASS'Y INSIDE ENCLOSURE. (NOT SHOWN)

ITEM	QTY.	PART NUMBER	DESCRIPTION
1	1	(SEE CHART)	BACK
2	1	(SEE CHART)	TOP
3	2	1003198	HINGE
4	4	1001290	SCREW, 10-32 X 5/16
5	1	(SEE CHART)	LABEL (U/L LISTING)
6	1	1002942	LABEL, RATING
7	2	1002880	BAG ASSY.

SUFFIX	BACK #	COVER #
-SU	1011986	1011990
-SUC	1128881	1128860
-SO	1128882	1128861
-SUNK	1011988	1011990
-NK	1128884	1128861
-SUNKC	1128885	1128860

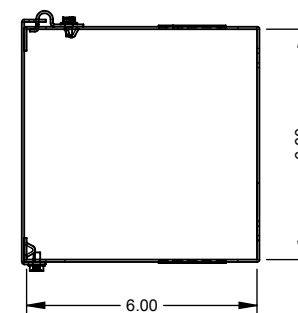

SUFFIX	FINISH
NONE	PAINTED
-NP	NOT PAINTED

REV	DATE	DESCRIPTION	BY
D	8-28-07	REDRAWN IN SW & ADDED BACK & COVER CHART ECO. 15946	DL
D1	4/10/08	ADDED CHART & REMOVED NOTE #2 (ECO.17139)	JLT

Material:	16 GA. - SEE CHART		
Shear/ Die#:			
Finish:	SEE CHART	General Offices: Kansas City, MO	
Part Wt.:		Title:	HINGE COVER WIREWAY 6 x 6 x 24, TYPE 1 NEMA ENCLOSURE
Tolerances: Unless Specified Otherwise X.X ±.1 X.XX ±.03 X.XXX ±.015 X" ±.2"		Catalog No.:	6624-GHC1
Third Angle 		Customer:	MILBANK STANDARD
Scale:	NTS	Drawing No.:	357
Drawn By:	DL	Date:	8-28-07
Checked By:		Sheet	1 of 1
Approved By:			