

Vornado Pendant

PD-87720 / PD-87723 / PD-87735

dweLED
by WAC Lighting




Fixture Type:

Catalog Number:

Project:

Location:

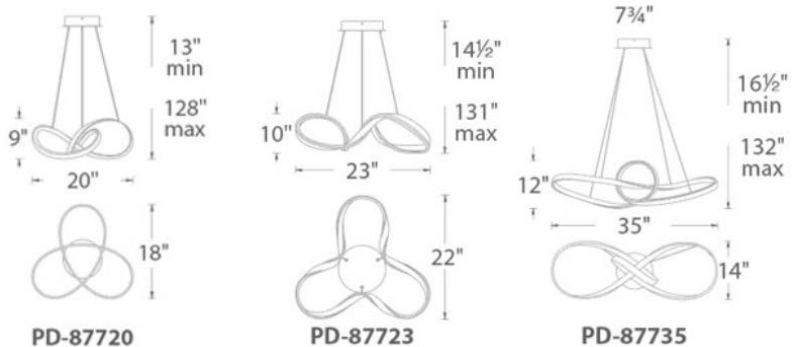

PRODUCT DESCRIPTION

Harmony out of chaos, Vornado is a free flowing mobius strip of high powered LED illumination. A simple, yet dynamic piece, Vornado is hand crafted to perfection. The silicon diffuser maximizes brightness and eliminates LED hot spot. Vornado is suspended on four thin low-profile cables without the need for an additional power cord, lending to a simple and minimalistic design. Adjustable to different lengths through a push-pin locking mechanism at the canopy.

FEATURES

- Flexible composite diffuser
- Thin powered cables provide an ultra-clean look
- Suspension height can be adjusted easily with quick release
- Fasteners maintain tension to hold fixture level
- Can be mounted on a sloped ceiling
- Universal voltage driver (120V-220V-277V) concealed within canopy

SPECIFICATIONS

Color Temp: 3000k

CRI: 90

Dimming: 100% - 5% ELV, 0-10V (20")
100% - 10% ELV (23" & 35")

Rated Life: 60,000 hrs

Input: 120-277V

Construction: Aluminum with composite diffuser

Finish: Chrome, White

Standards: ETL & cETL listed, Damp

ORDER NUMBER

Model	Wattage	Voltage	Delivered Lumens	Finish
PD-87720	20" 30W	120V-277V	2075	CH Chrome
PD-87723	23" 52W		3110	
PD-87735	35" 52W		2550	WT White

Example: PD-87735-CH

dweLED.com
Phone (800) 526.2588
Fax (800) 526.2585

Headquarters/Eastern Distribution Center
44 Harbor Park Drive
Port Washington, NY 11050

Central Distribution Center
1600 Distribution Ct
Lithia Springs, GA 30122

Western Distribution Center
1750 Archibald Avenue
Ontario, CA 91760