

OWS-FC-202-LED

LED Half Moon Wall Sconce
with Downlight Series

50 Wattage / 5000 Lumens

Catalog Number:

Project Name:

Note:

Type:



APPLICATIONS:

The architectural LED wall sconce provides efficient long-lasting light ideal for wall wash and facade lighting. Designed for walkways, entryways, and general perimeter lighting. Full cut-off meets Dark Sky requirements.


FEATURES:

- Lumen output of 5000lm with efficacy of 100lm/W
- 50W power consumption, to replace 200W MH
- Photocell optional
- Optional battery back-up option for emergency egress lighting
- Type II polycarbonate optical lens
- Dimmable
- Operating temperature is -40°C to 50°C (-40°F to 122°F)
- UL/cUL wet location


SPECIFICATIONS:

LUMENS	5000 lumens
WATTAGE	50W
CCT	40K
CRI	80
LIGHT EFFICIENCY	100 lumens/watt
VOLTAGE	120-277 VAC
POWER FREQUENCY	50/60 Hz
FINISH	Bronze, White, Silver
APPLICABLE ENVIRONMENT	Dry/Damp/Wet location
WORKING TEMPERATURE	-40°C to 50°C

DIMENSION:

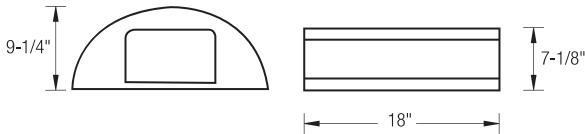

PHOTOMETRICS:

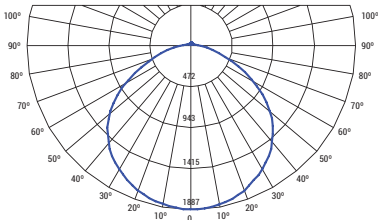

B	U	G
2	1	1



Ordering Guide > Example: OWS-FC-202-LED-5000L-DIM10-MVOLT-40K-BZ

OWS-FC-202-LED						
SERIES	PERFORMANCE	DIMMING	VOLTAGE	CCT	FINISH	OPTION
OWS-FC-202-LED	5000L - 5000 lumens	DIM10 - 0-10V Dimming	MVOLT - 120-277V	40K - 4000K	BZ - Bronze WH - White SI - Silver	PHC - Photocell

* Custom RAL, consult factory