



## Specification Sheet

# T8 EcoMax<sup>®</sup> Energy Saving Linear Fluorescent Lamp

Order Number **36012**

## Specifications


Energy Used (Watts).....	25
Domestic Code.....	F25T8/841/ECO/LL
Brightness (Lumens) .....	2500
Average Rated Hours (3 hrs./Start) .....	24000
Average Rated Hours (12 hrs./Start) .....	30000
Life (in years)* .....	21.9
Light Appearance (Kelvin) .....	4100
CRI .....	84
CIE Chromaticity .....	x.380, y.380
Efficacy (LPW).....	100
Estimated Yearly Energy Cost** .....	\$3.01
Country of Origin .....	China

## Physical Characteristics


Base .....	Medium BiPin
MOL.....	48"



## Lumen Maintenance

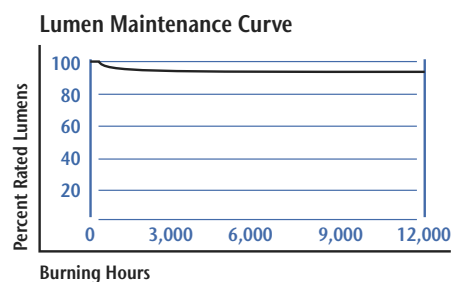

## Spectral Distribution

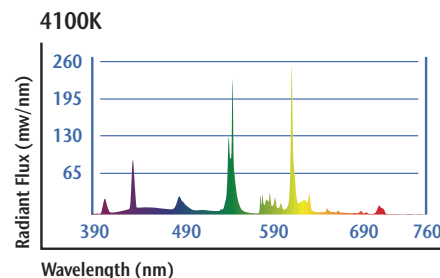

## Limited Warranty

This lamp is warranted to be free from defects in material and workmanship for 2 years (based on continuous usage 12 hours per day). If the product fails during the warranty period, return defective product to retailer. Warranty terms and conditions of retailer apply. If replacement product is not available at retail store, please return product, original package and receipt to manufacturer at: 12401 McNulty Road, Philadelphia, PA 19154-1029.

### TCLP Compliant

\* Based on 3 hrs./day

\*\* Based on 3 hrs./day 11¢/kWh - Cost depends on rates and use.

Contains mercury. For more on clean up and safe disposal, visit [epa.gov/CFL](http://epa.gov/CFL).

Call 1-800-999-2226 or visit [www.westinghouselighting.com](http://www.westinghouselighting.com)

Westinghouse Lighting Corporation, Philadelphia, PA 19154-1029, U.S.A. Westinghouse Lighting Corporation, a Westinghouse Electric Corporation licensee  
 ® "Westinghouse" and "You can be sure...if it's Westinghouse" are all registered trademarks of Westinghouse Electric Corporation

