


# ALLIANCE

## Specification Sheet

### Model: PL100 (Path Light)

Fixture Height: 19.1 in. (48.6 cm)  
 Fixture Length: 10 in. (25.4 cm)  
 Stem Diameter: 1.6 in. (4.1 cm)  
 Hat Height: 4.2 in. (10.8 cm)  
 Hat Diameter: 5.2 in. (13.3 cm)

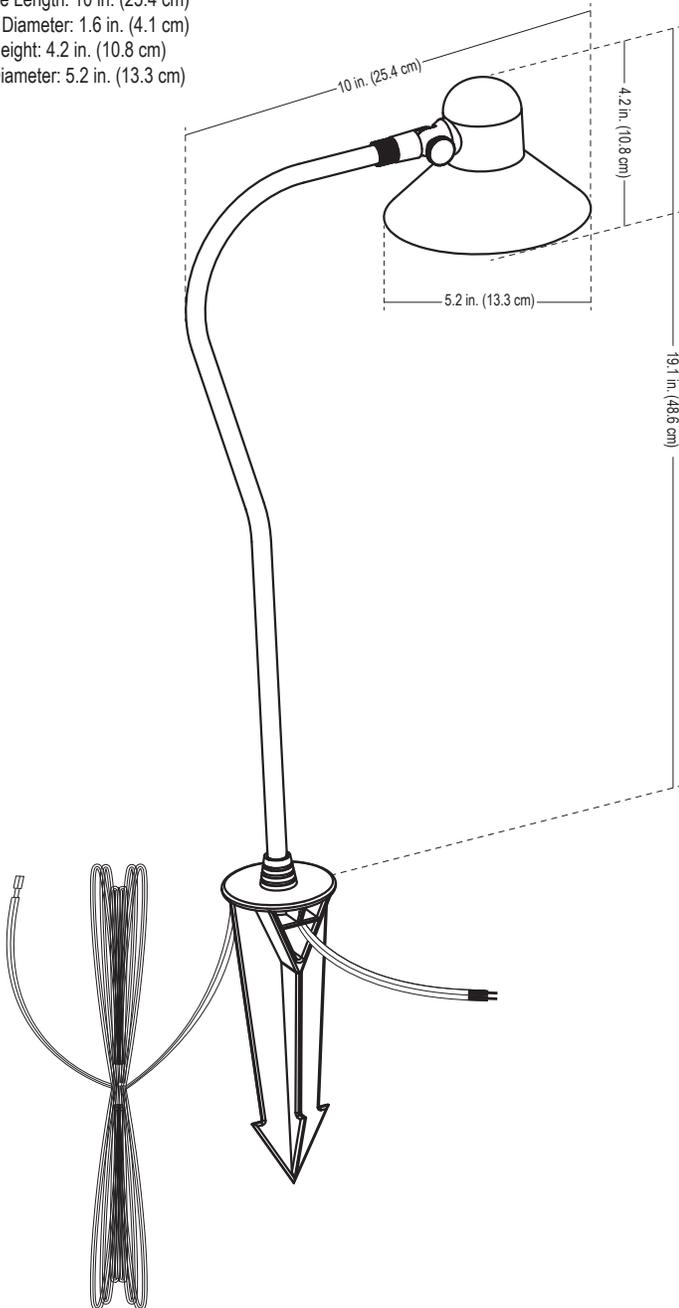

Notes:

Project:
Type:

#### Specifications and Features:

- Body:** Brass fixture, aged brass finish
- Hat:** Solid brass hat with dual adjustments, Brass thumb screw for vertical adjustments, Brass stem nut for horizontal adjustments
- Socket:** Spring loaded ceramic bi-pin socket with dual contact
- Lens:** Frosted bubble lens
- Wire:** Industry First, double wire lead pre-connected to the fixture, 16 awg (*UL listed*), brown
  - 25 foot wire lead, pre-stripped for easy wire connection
  - 18 inch wire lead, LED connection ready
- Stake:** Plastic ground stake, attached to the fixture (8.5 in; 21.6 cm length)
- Warranty:** Lifetime warranty on fixture housing
- Certification:** Complies with the requirements of UL-1838 and CAN/CSA-C22.2 No. 250.7. Identified with the ETL and cETL Listed Mark.




#### Lamp Options

Model #	Base Type	Wattage	Lumen Output
LBIPIN-LED-3W	Bipin/G4	3w	150lm
LXELOGEN-20 (Halogen)	Bipin/G4	20w	150lm

LED Ordering Guide: Model-LED  
 Example: PL100-LED

Project:
Type:

### Model: LBIPIN-LED-3W (3 watt BIPIN LED)

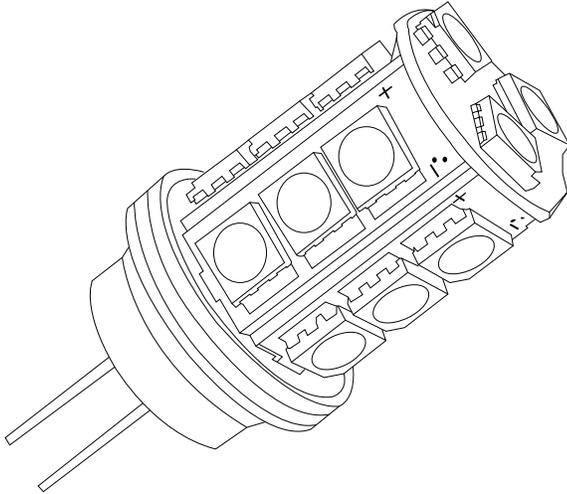

#### Specifications and Features:

- Watts:** 3
- Base Type:** G4/BiPin
- Light Output:** 150 lumens
- Color:** Warm White
- Color Temperatures:** 2700K
- Operating Voltage:** 8-24v
- CRI:** Ra>80
- LED Chip Qty:** 18 Pieces
- Halogen Equivalent:** 20w
- Rated Hours:** 50,000 hrs
- Ambient Operating Temperature:** <72°C
- Transformer Compatibility:** Must be powered by magnetic transformer
- Warranty:** Five year limited warranty on LED components

#### Lamp Color Options

Model #	Color	Color Temp.	Base Type	Wattage	Lumen Output
LBIPINLED-3W-3K	Bright White	3000K	BIPIN/G4	3w	150lm
LBIPIN-LED-3W-AMBER*	Amber	Amber	BIPIN/G4	3w	150lm

\*Turtle Safe

Notes: