



Standard LED bulbs

BC8A19/LED/RED/ND 120V 6/1

Standard LED bulbs are compatible with existing fixtures with a E27 holder and are designed for retrofit replacement of incandescent, halogen and energy saving bulbs. They deliver huge energy savings and minimize maintenance costs. The Standard LED bulb is the perfect bulb for your basic lighting needs. It provides the beautiful light and performance you expect from the LED technology at an affordable price.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
Nominal Lifetime (Nom)	10950 h
Technical Type	8-60W
Light Technical	
Color Consistency	<6
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8 W
Lamp Current (Nom)	125 mA
Wattage Equivalent	60 W
Warm Up Time to 60% Light (Nom)	0.5 s
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	82 °C

Controls and Dimming	
Dimmable	No
Approval and Application	
Energy Consumption kWh/1000 h	8 kWh
Product Data	
Order product name	BC8A19/LED/RED/ND 120V
EAN/UPC - Product	046677463212
Order code	463216
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	6
Material Nr. (12NC)	929001224103
Net Weight (Piece)	0.067 kg

Standard LED bulbs

Dimensional drawing

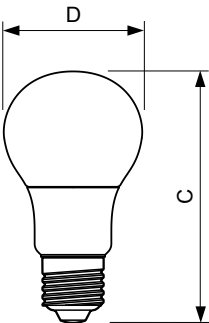

Product	D	C
BC8A19/LED/RED/ND 120V	61 mm	107 mm

Bulb A19 Red 120V 5.5W-40W 2700K E26 ND

