



Color:  Ivory

UPC Code: 07847724045

Country Of Origin: Please Contact Customer Service.

## 1221-LHI

20 Amp, 120 Volt, Toggle Lighted Handle - Illuminated OFF Single-Pole AC Quiet Switch, Industrial Grade, Self Grounding, Back & Side Wired, - Ivory

Leviton's Industrial Grade AC toggle switches for extra heavy-duty applications represent top-of-the-line quality and peak performance. Leviton uses the finest materials available and the highest production standards to produce industrial switches of unmatched versatility and reliability.

### Technical Information

#### AC Horsepower Ratings

**HP Rating:** 1HP-120V

**Max. Amperage:** 16 Amp

#### Electrical Specifications

**Amperage:** 20 A

**Dielectric Voltage:** Withstands 1500V for 1 minute

**Endurance:** 50,000 cycles minimum

**Grounding:** Self-Grounding

**Overload UL20 Test:** 100 cycles of OL at 4.8 times rated current

**Temperature Rise:** Maximum 30 degrees C rise

**Voltage:** 120 VAC

#### Environmental Specifications

**Flammability:** Rated V-2 per UL 94

**Operating Temperature:** -40°C to 65°C

#### Material Specifications

**Base Material:** Thermoplastic

**Color:** Ivory

**Contact Material:** Silver Alloy

**Cover Material:** Thermoplastic

**Ground Clips:** Brass

**Grounding Screw:** Brass 8-32

**Strap Material:** Steel

**Terminal Screws:** Brass 8-32

**Toggle:** Polycarbonate

#### Mechanical Specifications

**Product ID:** Ratings are permanently marked on device

**Terminal Accom.:** 14-#10 AWG back wired; #14-#12 AWG side wired

**Terminal ID:** Brass-Hot Black-Hot White-Neutral Green-Gnd

**Termination:** Back or Side Wire

**Torque Range:** 12-14 inch pounds

#### Product Features

**Actuator Material:** Polycarbonate

**Body Material:** Thermoplastic

**Color:** Ivory

**Device Type:** Toggle Switch

**Feature:** Illuminated - Load OFF

**Function:** Single-Pole

**Grade:** Extra Heavy-Duty Industrial Specification Grade

**Grounding:** Self-Grounding

**Strap Material:** Steel

#### Standards and Certifications

**ANSI:** C-73

**CSA C22.2 No. 111:** File #152105

**NEMA:** WD-1 & WD-6

**NOM:** 057


**RoHS:** Compliant

**UL Fed Spec WS896E:** File #E7458


**UL Standard:** UL 20

**Warranty:** 10 Year Limited

## Dimensional Diagram

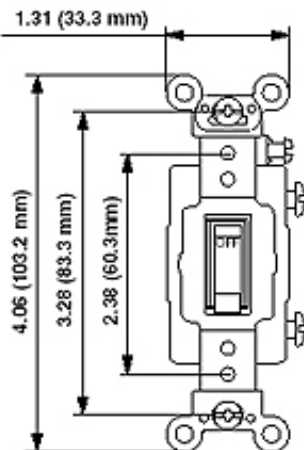

## Wiring Diagram Single-Pole Lighted

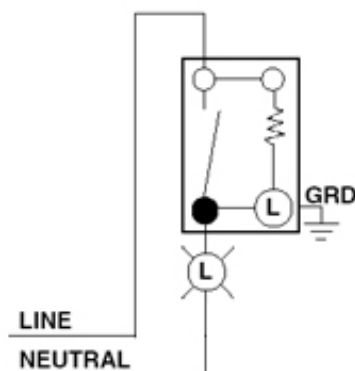

## SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

### Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Telephone: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday):  
+1-800-824-3005

### Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·  
FAX: +1-800-824-3005 · [www.leviton.com/canada](http://www.leviton.com/canada)

### Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-  
1797 · [www.leviton.com.mx](http://www.leviton.com.mx)

Visit our Website at: [www.leviton.com](http://www.leviton.com)

© 2018 Leviton Manufacturing Co., Inc. All Rights Reserved. Subject to change without notice.

### Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:  
[www.leviton.com/international/contacts/](http://www.leviton.com/international/contacts/)

