



7600

Tactical Flashlight

Combining the latest lighting technology along with an array of features while maintaining a compact design make the Pelican 7600 one of the best all round law enforcement flashlights available.

Performance surpassing 900 lumens coupled with a USB rechargeable lithium ion battery are just the beginning of this multi-talented product. In addition to the extreme high performance white LED light output, a red and green LED are included. These additional colors provide values such as night vision preservation and can be used for traffic control when partnered with a slip-on wand accessory.

The 7600 provides high, strobe, medium and low modes. You are able to choose from 5 different programs to personalize these modes to your liking. The full time battery level indicator ensures you will always know where your battery status is. Plated with a Type III hard anodizing finish provides the most robust finish. The ability to use disposable CR123 batteries if power is unavailable ensures you'll never be without light when it is needed most. The removable pocket clip and its IPX8 submersible status rounds out the many features on the Pelican 7600.

- USB Lithium Ion Rechargeable
- 3 LED Colors
- Selectable Modes
- Full Time Battery Level Indication
- Type III hard anodized finish
- Ingress Protected IPX8 Submersible
- Unconditional Lifetime Guarantee of Excellence



CONFIGURATIONS



7600
Standard



7600COMBO
Flashlight / Wand / Holster Combo

MATERIALS

Body	Aluminum with Type III Anodized
O-Ring	NBR
Lens	AR Coated Glass
Clip	High Carbon Steel
Contact Spring Retainer	Stainless Steel / Phosphore Bronze / Brass Nickel Plate

COLORS

- Black

LIGHT SPECS

Lamp Type	LED
------------------	-----

POWER

Battery Size	18650
Battery Type	Lithium-Ion
Battery Quantity	1



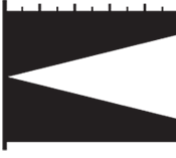


Batteries Included yes
Charge Time 5 hrs
Battery Level Indicator RGB LED
Volts 3.7v

WEIGHT

Weight With Batteries 6.9 oz (196 gr)
Weight Without Batteries 5.4 oz (153 gr)

SWITCH

Switch Type Push Button
Light Modes High / Strobe / Medium / Low

FL1 STANDARD	HIGH	MEDIUM	LOW
	944 LUMENS	479 LUMENS	37 LUMENS
	3h 15mins	4h 30mins	29h 0mins
	225m	157m	44m
	12693cd	6172cd	480cd
	IPX8 (1m)		

ACCESSORIES



7606
Nylon Holster



7607
Holster / Wand Kit



2389
Replacement Battery



2386
USB Charger and Battery



7608
Plastic Holster

Pelican

23215 Early Ave • Torrance, CA 90505 USA • Phone: (310) 326-4700 • (800) 473-5422 • Fax: (310) 326-3311
sales@pelican.com • www.pelican.com