



## LL4R - 27K

### The Ultimate 4" Super Thin Recessed LED 13.5W Warm White

#### Type IC, Wet & Air-Tight



#### DESCRIPTION


Recessed 4" Round LED With Integral Driver In Connection Box.  
Fits Where No Other Recessed Fixture Can.

#### FEATURES & BENEFITS

**1/2" Thin** - Install Directly Under Joists, Maximum Layout Flexibility  
**Driver Inside Connection Box** - No Junction Box Needed  
**Fast & Easy To Install** - Save On Labour  
**Type IC Rated** - No Housing Required  
**CRI > 90** - True Colour Rendering  
**Wide Trim** - No More Goof Rings  
**Wet Location Approved**

#### MOUNTING

Cut Hole In Ceiling And Snap Fixture In Opening With Attached Spring Clips.  
2" Above Ceiling Clearance Required For Driver.

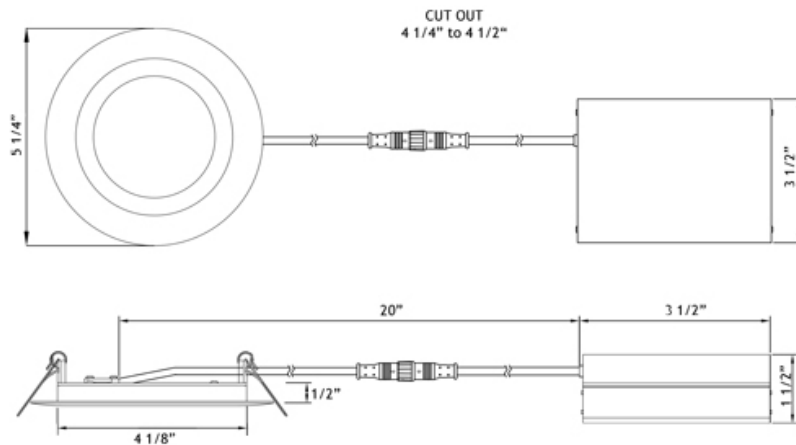

#### Driver Included



#### Trim Options



White

Black

Brushed Nickel

Brushed Copper

#### COMPLIANCE



#### Warehouses

Vancouver

Toronto

Las Vegas

Naples

Philadelphia

Dallas

Seattle

tel: 1-844-24-LOTUS (56887)

fax: 1-877-561-6306

www.lotusLEDlights.com

## CHARACTERISTICS

**Body:** Durable, Die Cast Aluminum Alloy for Optimal Heat Dissipation.

**Paint:** Oil Based Spray Painted - Scratch Resistant And Smooth Finish.

**LEDs:** 48 Pieces Of Custom Packaged LM80 Epistar 2835. CRI > 90.

Guaranteed 98% Lumen Maintenance After 6,000 Hours.

Strict Binning To Ensure Consistent Light Colour.

**Driver:** 4th Generation Lotus Designed. Field Proven Since 2011.

**Connection Box:** Patented Invention By Lotus LED Lights.


Saves Contractors Labour On Installation.

**Testing:** Every Single Driver Is Powered For Minimum 24 Hours

Together With The Fixture That It Is Shipped With.



Every LED Is Visually Checked Before And After The PCB Is Mounted On The Fixture.

No Random Tests - We Hand Test Every Fixture & Driver.

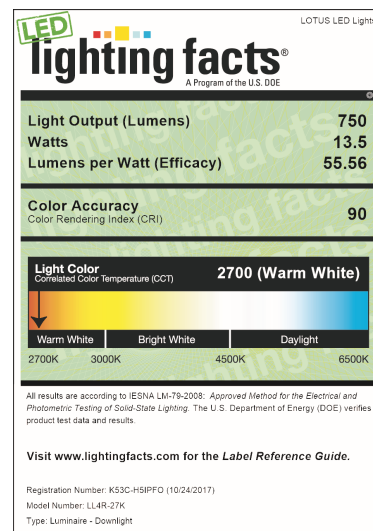

## PHOTOMETRIC DATA OF A LAB TESTED SAMPLE

MODEL:	LL4R-27K	LAMP FLUX:	754 LM
VOLTAGE:	120 V	LUMENS / POWER:	57 LM/W
POWER:	13.17 W	CENTRAL INTENSITY:	278 CD
PF:	0.99	BEAM ANGLE:	107 DEGREES

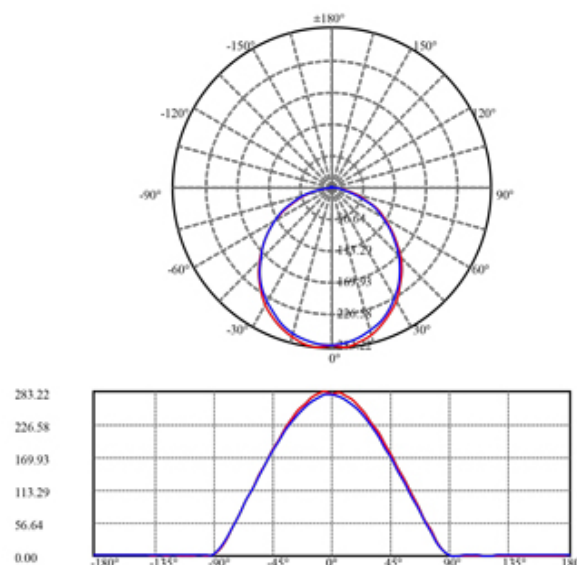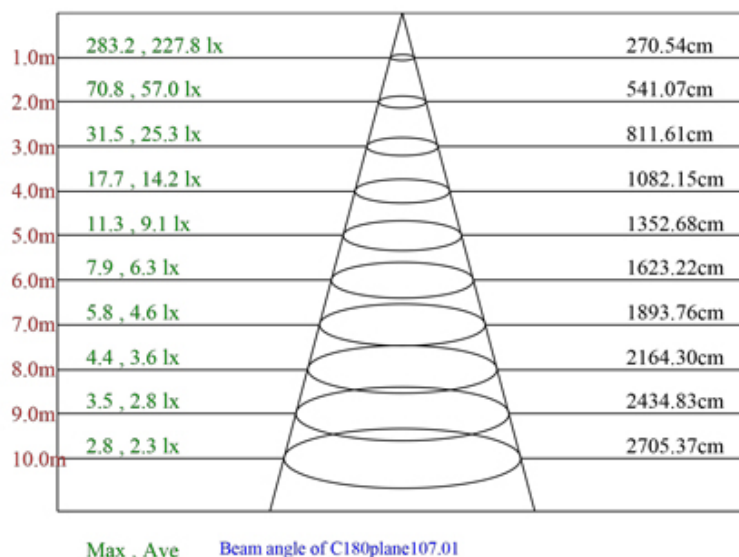

## ORDERING GUIDE

Example: LL4R - 27K - WH

LL4R - 27K -

Trim Finish

WH : White


BK : Black

BN : Brushed Nickel

BC : Brushed Copper

## ACCESSORIES

Sold Separately

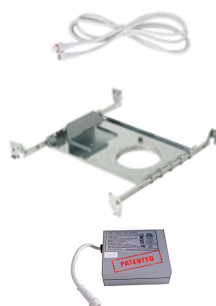

Low Voltage Extension Cables  
6ft - cat # EXC6, 20ft - cat # EXC20  
Max 40 ft Extension Allowed

Flanged Rough-In Plates - cat # LRP412

Order 277V - 347V Optional Driver  
Separately As cat # LLL-LD1535H



Lotus  
LED  
Lights

## Warehouses

Vancouver

Toronto

Las Vegas

Naples

Philadelphia

Dallas

Seattle

tel: 1-844-24-LOTUS (56887)

fax: 1-877-561-6306

[www.lotusLEDlights.com](http://www.lotusLEDlights.com)