

**APPLICATION:**

For concrete use only

BODY:

High grade die-cast aluminum with 0.3% copper to prevent corrosion in concrete applications. Supplied standard with three 3/4" NPS holes located on top, side & back

FACE PLATE:

High-grade die-cast aluminum

GASKET:

Single-piece molded silicon for wet location

LENS:

Frosted tempered glass

FINISH:

White, Satin Aluminum, and Bronze thermoset powder coat

EXTERNAL LOUVER:

Anodized 45° cut-off louver

REFLECTOR:

High-performance aluminum reflector assembly for superb light output

INSTALLATION:

Two 1/2" NPS wiring holes
Feed through listed

DRIVER:

Driver included

LISTING:

UL/C-UL for wet location




ST701



ST702



ST703

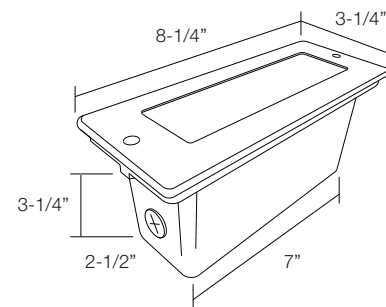

Ordering Guide ▶ Example: ST7BX-LED-WW-12V-ST701-WH

HOUSING TYPE/WATTAGE	
LED	
ST7BX-LED-WW-12V*	- 3W LED 12V
ST7BX-LED-CW-12V*	- 3W LED 12V
ST7BX-LED-WW-120V	- 3W LED 120V
ST7BX-LED-CW-120V	- 3W LED 120V

FACE PLATE
ST701
ST702
ST703

FINISH
WH - White
BK - Black
BZ - Bronze
SN - Satin Nickel
AL - Satin Aluminum

HOUSING AND FACE PLATE MUST BE ORDERED SEPARATELY

***MUST BE USED WITH REMOTE TRANSFORMER**