



Color:  Brown

UPC Code: 07847739213

Country Of Origin: Mexico

NEMA:
5-20R



TDR20

Brand Features

Plug Into Safety with Leviton's Line of Tamper-Resistant (TR) Receptacles. Leviton makes it easy for you to comply with the current NEC mandate for TR Receptacles in all new residential housing. This requirement resulted from a Consumer Product Safety Commission study, that reported alleged injuries in the home caused each year by children attempting to insert foreign objects into receptacles. TR receptacles have been mandated in pediatric care areas for over 20 years and have likely been successful in preventing electrical injuries. As a long-time manufacturer of tamper-resistant devices, we are pleased to be at the forefront of this safety measure with an expanded product line that encompasses a wide range of TR devices in Residential, Commercial, Industrial and Hospital Grades.

Item Description

Decora Plus Duplex Receptacle Outlet, Heavy-Duty Industrial Specification Grade, Tamper-Resistant, Smooth Face, 20 Amp, 125 Volt, Back or Side Wire, NEMA 5-20R, 2-Pole, 3-Wire, Self-Grounding - Brown

Technical Information

AC Horsepower Rating

Horsepower Rating: 1 HP

Electrical Specifications

Amperage: 20 Amp

Dielectric Voltage: Withstands 3000 V minimum

Grounding: Self-Grounding

Pole: 2-Pole

Temperature Rise: Max 30 °C temperature rise at full rated current

Voltage: 125 Volt

Wire: 3-Wire

Environmental Specifications

Flammability: UL94 V0

Operating Temperature: Maximum Continuous 75 °C, minimum -40 °C (w/o impact)

Material Specifications

Body Material: PBT Polyester Blend

Face Material: PBT Polyester Blend

Ground Clips: Brass

Ground Contacts: 0.030" Brass

Grounding Screw: #8 Hex Head, Triple-Drive Brass

Line Contacts: 0.030" Phosphor Bronze

Mounting Screws: Triple-Drive Plated Steel

Shutter Mechanism: Acetal

Strap Material: Steel (Galvanized G60)

Terminal Clamps: Brass

Terminal Screws: #8 Triple-Drive Brass

Mechanical Specifications

Product ID: Ratings are permanently marked on device

Terminal Accom.: #14 AWG - #10 AWG

Terminal ID: Brass - Hot, Silver - Neutral, Green - Ground,

Termination: Back or Side Wire

Wire Type: Stranded or Solid

Product Features

Color / Feature: Brown

Device Type: Duplex Receptacle Outlet

Feature:

Grade: Heavy-Duty Industrial Specification Grade

NEMA: 5-20R

Color: Brown

Feature 2: Tamper-Resistant

Feature 4: Smooth Face

Standards & Certifications


ANSI: C-73

Applicable Standards: UL 498, Fed Spec W-C-596, CSA C22.2. No. 42

Certification/Listing: cULus, NOM-ANCE

NEMA: WD 1 & WD 6

RoHS: RoHS Compliant

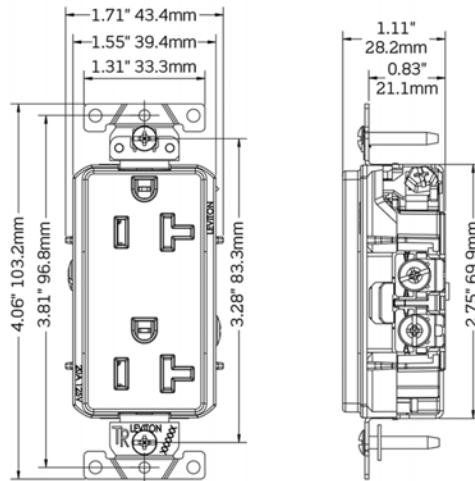

Drawing Applies to 15 & 20A Devices

SPECIFICATION SUBMITTAL

JOB NAME:	CATALOG NUMBERS:	
<input type="text"/>	<input type="text"/>	<input type="text"/>
JOB NUMBER:	<input type="text"/>	<input type="text"/>

Leviton Manufacturing Co., Inc.

201 North Service Road, Melville, NY 11747

Teléfono: +1-800-323-8920 · FAX: +1-800-832-9538 · Tech Line (8:30AM-7:30PM E.S.T. Monday-Friday): +1-800-824-3005

Leviton Manufacturing of Canada, Ltd.

165 Hymus Boulevard, Pointe Claire, Quebec H9R 1E9 · Telephone: +1-800-469-7890 ·

FAX: +1-800-824-3005 · www.leviton.com/canada

Leviton S. de R.L. de C.V.

Lago Tana 43, Mexico DF, Mexico CP 11290 · Tel.: (+52)55-5082-1040 · FAX: (+52)5386-1797 · www.leviton.com.mx

Visit our Website at: www.leviton.com

© 2018 Leviton Manufacturing Co., Inc. Todos los derechos reservados. Subject to change without notice.

Leviton has a global presence.

If you would like to know where your local Leviton office is located please go to:

www.leviton.com/international/contacts/

