

Surface/Recessed LED Down Lights

LED Down Light is a simple yet beautiful solution for flush mount and recessed applications without requiring the use of a recessed can. The DL-4-9D/DL-6-15D series features a 120V AC alternating current source which eliminates the need for a traditional LED driver. In addition, the DL-4-9D/DL-6-15D is wet location listed and installs easily on standard ceiling junction box or can be retrofitted to existing recessed cans with included hardware.



DIMMABLE



Features

- 120V AC source, no driver needed
- Installs easily on standard ceiling junction box with included hardware
- Included mounting springs allow existing recessed cans to be retrofitted
- Die cast aluminum trim routes heat away from electrical components
- White polycarbonate diffuser eliminates hot spots creating uniform light distribution
- Wet location listed suitable for virtually any application
- Suitable for use in IC or NON-IC Applications
- 90+ CRI, the absolute best in the industry
- Dimmable to 5% with most standard dimmers
- Approved by ETL Standards for Canada and USA
- Energy Star / T24 Compliant
- 5 year limited warranty

Applications


- Lobbies
- Hallways
- Banquet halls
- Elevators
- Stairways
- Retail
- Restaurants
- Residential

Specifications


Electrical	4" = 120V AC, 9W 6" = 120V AC, 15W
LEDs	Epistar
LED Life	50,000 hours
Luminous Flux	4" = 650 lumens 6" = 1000 lumens
Beam Angle	120°
Color Temperature	2700K – 4000K
CRI	> 90
Operating Temperature	-40C – +40C
Construction	Die cast aluminum, white polycarbonate lens
Finish	White, Rubbed Oil Bronze, Satin Nickel
Appearance Size (W x H)	4" = 5.1" x 0.6" (129.5mm x 152.0mm) 6" = 7.2" x 0.78" (182.9mm x 19.8mm)
Approvals	cETLus listed for wet locations, Energy Star rated

Product Codes

DL - X - XD - YY - ZZ				
Surface/Recessed LED Down Light	Fixture Size	Watt	Color Temperature	Trim Color
	4 - 4" fixture	9D - 9 watts	27 - 2700K	WH - White
	6 - 6" fixture	15D - 15 watts	30 - 3000K 40 - 4000K	RB - Rubbed Oil Bronze SN - Satin Nickel


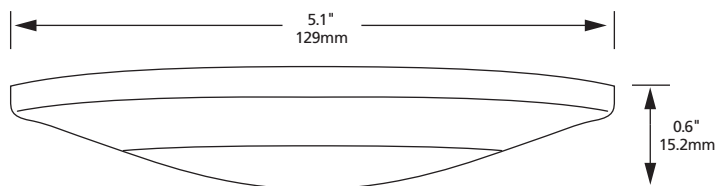


4" Surface/Recessed LED Down Light

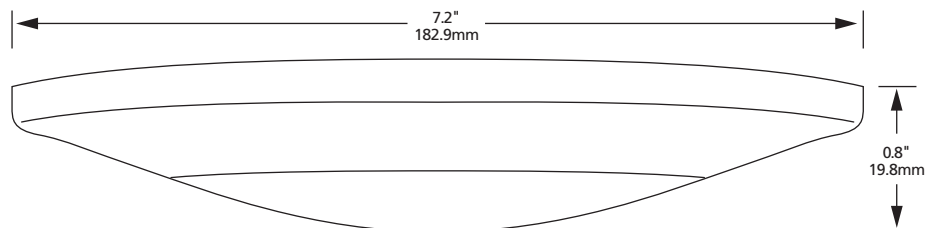

6" Surface/Recessed LED Down Light

Recessed Mounting

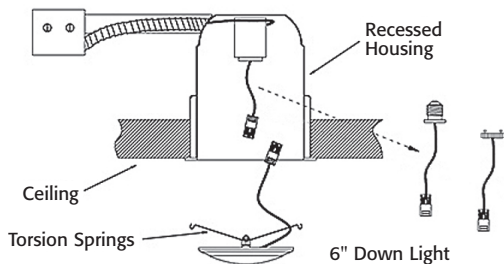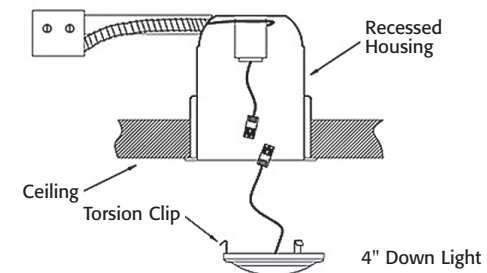

Junction Box Mounting

