


TEAFLEX





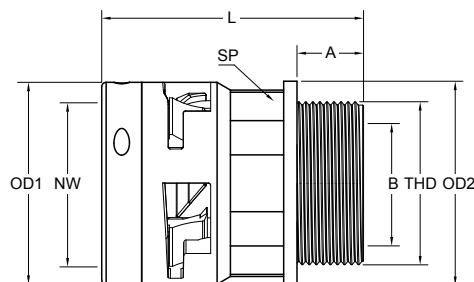



- Locking device system provides a quick and secure push-in connection of corrugated conduits
- High-grade formulated polyamide
- Self-extinguishing, free from halogens and cadmium
- Excellent impact strength
- Temperature range: -40°C(-40°F) to 105°C(221°F)
- Short-term to 160°C(320°F)
- Up to IP68 / NEMA 6P protection with the reinforced sealing cap at conduit side
- Colour: Black standard, other colours available upon request

IP RATING	SHAPE	THREAD TYPE
K8	M	S
12	N	02
COLOUR MATERIAL	SÉRIES TYPE	NW THREAD SIZE



Specifications are subject to change without notice

NPT
THREAD

	Order No.	Order No.	THD	Fits to Conduit			A		B		L		OD1		OD2		SP	
	IP66	IP68	NPT	NW	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	in
	K6-M-S-12N02	K8-M-S-12N02	1/2	12	16	3/8	13.5	0.53	14.0	0.55	46.0	1.81	24.0	0.94	26.0	1.02	20.0	0.79
	K6-M-S-17N02	K8-M-S-17N02	1/2	17	20	1/2	13.5	0.53	15.0	0.59	47.4	1.86	30.0	1.18	28.0	1.10	26.0	1.02
	K6-M-S-23N04	K8-M-S-23N04	3/4	23	25	3/4	14.0	0.55	20.0	0.79	57.0	2.24	38.0	1.50	38.0	1.50	32.0	1.26
	K6-M-S-29N06	K8-M-S-29N06	1	29	32	1	17.3	0.68	26.0	1.02	61.3	2.41	45.5	1.79	46.0	1.81	40.0	1.57
	K6-M-S-36N07	K8-M-S-36N07	1-1/4	36	40	1-1/4	18.0	0.71	33.7	1.33	70.0	2.76	57.0	2.24	54.0	2.13	50.0	1.97
	K6-M-S-48N09	K8-M-S-48N09	2	48	50	1-1/2	19.0	0.75	50.0	1.97	77.5	3.05	68.0	2.68	70.0	2.76	64.0	2.52