

Model No :: **23952-BS/OPL**
Name :: Nitrogen



Project Name :: _____
Location :: _____
Type :: _____
Quantity :: _____
Notes :: _____

Product Information

Product ID :: 23952
UPC Code :: 641594012057
Mounting Type :: Ceiling
Finish :: Brushed Steel (BS)
Diffuser :: Opal (OPL)
Alt. Finishes :: N/A
Alt. Diffusers :: N/A

Product Dimensions

Fixture	Canopy
Length :: N/A	Length :: N/A
Width :: N/A	Width :: N/A
Diameter :: 14	Diameter :: N/A
Extension :: N/A	Height :: 1.25
Height :: 12	
Overall Height :: 57 Max.	

Technical Specifications

Qualifications

Location Rating :: Dry
Certification :: cETLus
IES File :: No
JA8 Compliant :: No
Energy Star :: No
ADA Compliant :: No
Marine Grade :: No
Emergency Lighting :: No
Warranty :: 1 Year Limited

Specifications

Frame Material :: Metal
Diffuser Material :: Glass
Voltage :: 120v
Lamping Type :: Incandescent
Lamping Base :: E-26
Lamp Quantity :: 1
Lamp Wattage :: 100 W
Total Wattage :: 100 W
Lamps Included :: No
J-Box Type :: Standard

Photometrics


CCT :: 2700
CRI :: N/A
Wattage :: 100 W
Nominal Lumens :: 1600
Delivered Lumens :: N/A

Recommended Dimmers

(TRIAC) Any Standard Dimmer

Custom Options :: N/A; **Additional Items** :: 6, 16, and 22-inch down rods included, 10 feet of cord included, Sloped ceiling adapter included

Line Drawing #1

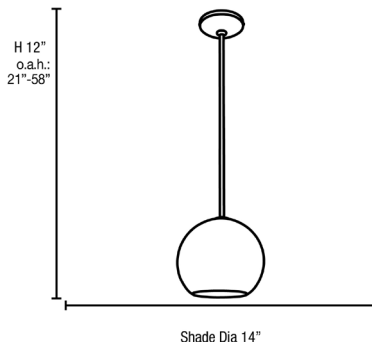

Line Drawing #2

Image
Not Available

IES File

Image
Not Available

Toll Free 800-828-5483 or www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information provided is subject to change without notice. ©2018 Access Lighting Corporation. All Rights Reserved
Rev. 201809 Filename:: 23952-BS_OPL.pdf

