



Weight: 0.9 lbs

Project:	Type:
Prepared By:	Date:

Driver Info		LED Info	
Type	N/A	Watts	0W
120V	N/A	Color Temp	N/A
208V	N/A	Color Accuracy	N/A
240V	N/A	L70 Lifespan	N/A
277V	N/A	Lumens	N/A
Input Watts	0W	Efficacy	N/A

Technical Specifications

Listings

UL Listed:

Suitable for wet locations in a covered ceiling

Construction

IC Rating:

Suitable for direct contact with insulation

Housing:

Precision die cast aluminum

New Construction:

Nailer bars are provided for use with wood joist installations

Green Technology:

Mercury and UV free. RoHS-compliant components.

Finish:

Formulated for high durability and long-lasting color

Other


Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of five (5) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at www.rablighting.com/legal#warranty

Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

Dimensions

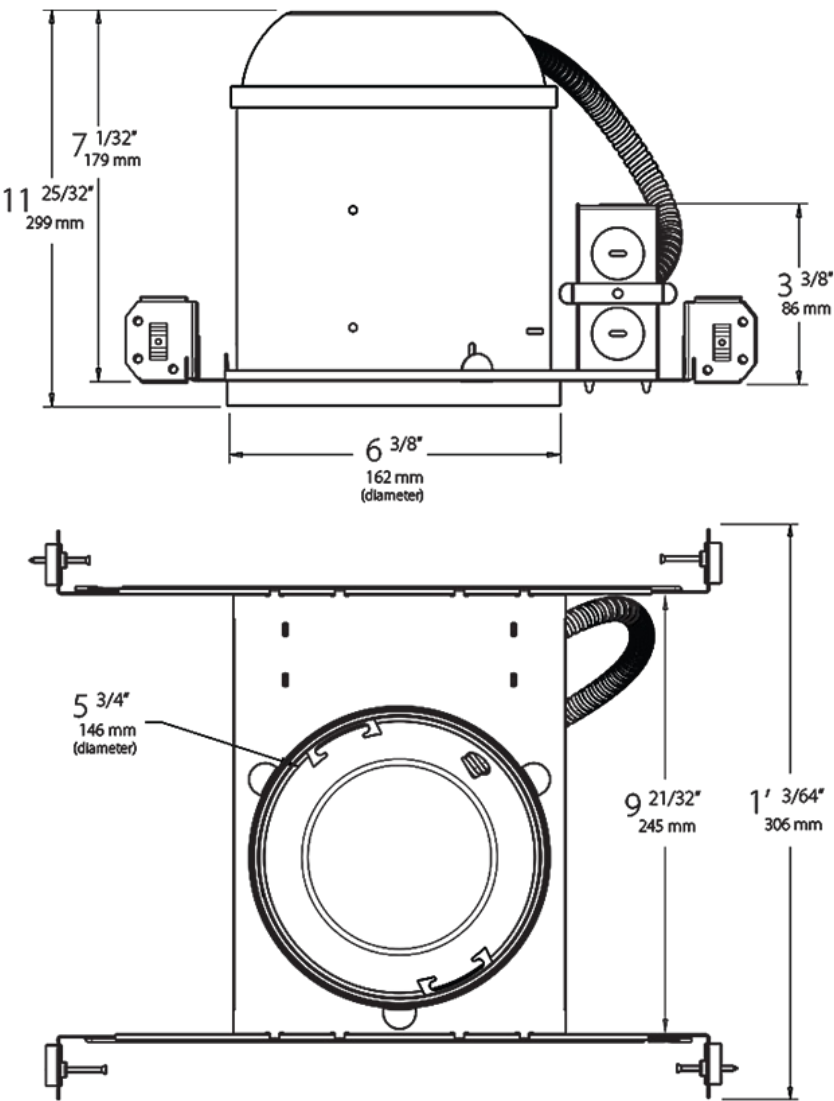

Ordering Matrix

Family	Size	Shape	Housing
NDCANIC	6	R	
	4 = 4"	R = Round	NDCANIC = New Construction
	6 = 6"		RDCANIC = Remodeler