



A-Shape LED

5.5A19/PER/827/P/E26/DIM 6/1FB


Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

General Information		Warm Up Time to 60% Light (Nom)		0.5 s
Cap-Base	E26 [Single Contact Medium Screw]	Power Factor (Nom)		0.8
Nominal Lifetime (Nom)	15000 h	Voltage (Nom)		120 V
Switching Cycle	50000X			
Technical Type	5.5-40W	Temperature		
		T-Case Maximum (Nom)		85 °C
Light Technical		Controls and Dimming		
Color Code	827 [CCT of 2700K]	Dimmable		Yes
Beam Angle (Nom)	250 °			
Initial lumen (Nom)	450 lm	Mechanical and Housing		
Luminous Flux (Rated) (Nom)	450 lm	Bulb Finish		Frosted (FR)
Color Designation	Warm White (WW)			
Correlated Color Temperature (Nom)	2700 K	Product Data		
Luminous Efficacy (rated) (Nom)	81.00 lm/W	Order product name		5.5A19/PER/827/P/E26/DIM 6/1FB
Color Consistency	<6	EAN/UPC - Product		046677479848
Color Rendering Index (Nom)	80	Order code		479840
LLMF At End Of Nominal Lifetime (Nom)	70 %	Numerator - Quantity Per Pack		1
		Numerator - Packs per outer box		6
Operating and Electrical		Material Nr. (12NC)		929001836104
Input Frequency	60 Hz	Net Weight (Piece)		0.084 kg
Power (Rated) (Nom)	5.5 W			
Lamp Current (Nom)	65 mA			
Wattage Equivalent	40 W			
Starting Time (Nom)	0.5 s			

A-Shape LED


Dimensional drawing

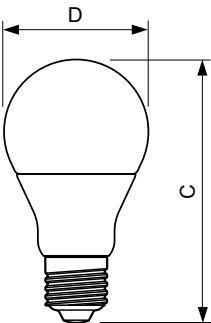


Bulb A19 120V 5.5-40W 450lm 2700K E26 D

Product	D	C
5.5A19/PER/827/P/E26/DIM 6/1FB	62 mm	111.3 mm


Photometric data

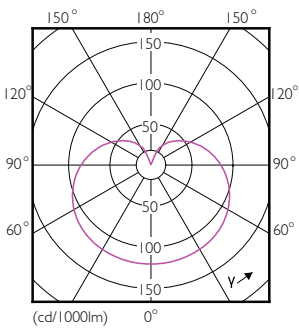

40W E26 A19 FR 250D 827 2700K

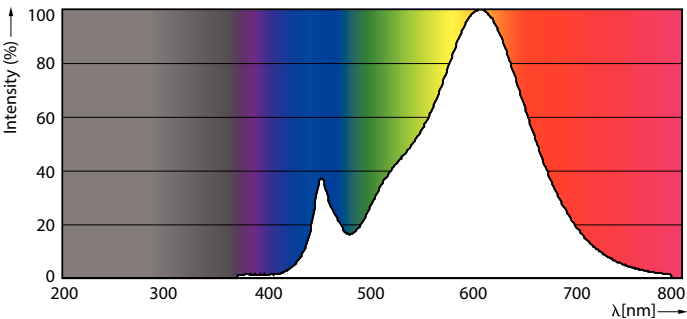


40W E26 A19 FR

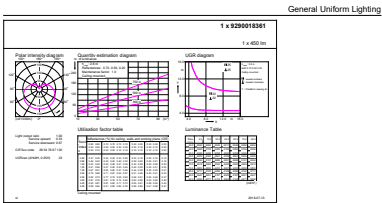


A-Shape LED

Lifetime

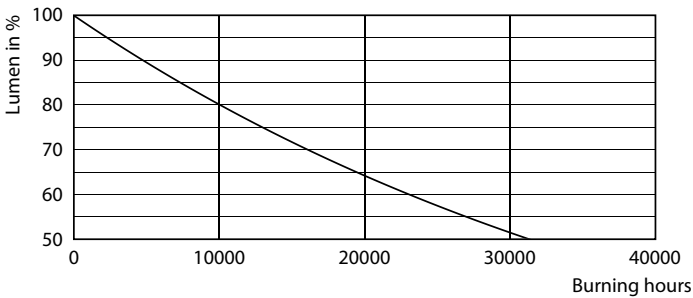

40W E26 A19 FR

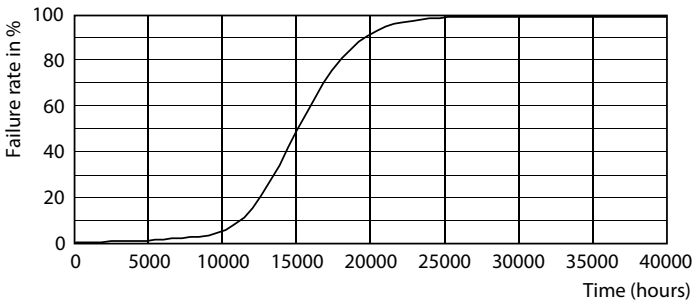

40W E26 A19 FR

