




PRODUCT DESCRIPTION

Knoxville EE is a cross between transitional and traditional styles in Bronze finish. Is part of our energy saving collection.

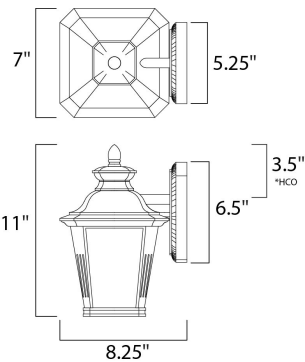

\*height from center of outlet to the top of the fixture

MEASUREMENTS

DIMENSION : 7." W x 11." H x 8.25" Ext  
BACK PLATE : 5.25" W x 6.5" H x 3.5" HCO  
HANGING WEIGHT : 2.49 lb

LAMPING

INPUT VOLTAGE : 120V  
LUMENS : 900 Rated  
BULB : 1 x 13W (INCLUDED), 13W Total  
COLOR\_TEMP : 2700K

FINISHES OPTION

Bronze BZ



GLASS

Frosted Seedy FS

MATERIAL

Die Cast Aluminum

RATINGS

Wet Location



ADDITIONAL

INSTALL UP/DOWN:  
RATED LIFE 10000 Hours  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746  
EASTERN DISTRIBUTION CENTER  
4200 SHIRLEY DR. | ATLANTA, GA 30336  
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com