



**MCR  
SAFETY**

# MU3624

## Mustang

### Drivers

### Specification Sheet

#### **PRODUCT DESCRIPTION:**

Whether you're prepping a tie off or wrangling a transmission pole, you will need a glove that works as hard as you do. The men and women of the utility industry are the most dependable workers in the world. That is why they rely on an industry leader to provide the best protection for them. The top grain leather of the MCR Safety Mustang Utility field glove offers the dexterity that allows you to feel what you're working with and holds up to the abrasion better than split leather. The MU3624 features a premium brown goatskin leather which remains soft and comfortable during sweaty conditions. Strategically positioned second layers of premium brown goatskin in the palm, fingertips, thumb crotch, index finger and knuckle provide additional protection without sacrificing dexterity. It is double stitched with DuPont™ Kevlar® thread on all stitch lines to provide longer wear life and to prevent seam blowout. The arc rated MU3624 has a rating of 14 cal/cm<sup>2</sup> /HRC2. This field glove will provide all day protection and comfort to get the job done.



#### **FEATURES:**

- Premium brown goatskin leather
- A second layer of premium brown goatskin in the palm, fingertips and knuckle
- Wing style thumb
- Sewn with DuPont™ Kevlar® thread
- 14 cal/cm<sup>2</sup> HRC2 / ARC2
- Shirred elastic around entire wrist

#### **APPLICATIONS:**

Utilities, Cable , HVAC, Construction, Carpentry, Demolition, Landscaping, Farming

#### **TECHNICAL DATA FOR: MU3624L**

<b>Series</b>	Mustang	<b>Overall Length</b>	9.5 in.
<b>Material Group</b>	Leather	<b>Limited Flamability</b>	Yes

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA  
Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2019 MCR Safety - All Rights Reserved



**MCR**  
**SAFETY**


# MU3624

## Mustang

### Drivers

### Specification Sheet

<b>Product Type</b>	Drivers	<b>ANSI Puncture</b>	ANSI Puncture 3
<b>Glove Size</b>	Large	<b>ANSI Abrasion</b>	ANSI Abrasion 3
<b>Material</b>	Leather	<b>ANSI Contact Heat</b>	Level 3 (Applications less than 392 degrees F)
<b>Leather Cut</b>	Grain		
<b>Leather Type</b>	Goat Skin		
<b>Grade</b>	Premium		
<b>Features</b>	Sewn With KEVLAR		
<b>Lining</b>	Unlined		
<b>Pattern</b>	Gunn		
<b>Thumb Style</b>	Wing		
<b>Thickness</b>	0.7 - 0.8 mm		
<b>Made In</b>	Pakistan		

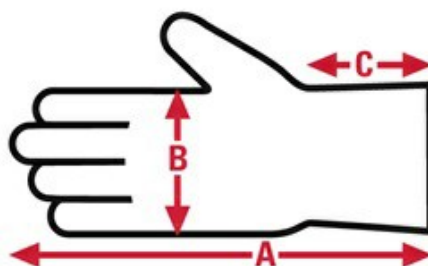

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
MU3624M	Medium	0	0	N/A	27.480 lb.	0.229
MU3624XL	X - Large	0	0	N/A	32.400 lb.	0.270
MU3624XXL	XX - Large	0	0	N/A	35.760 lb.	0.298
MU3624L	Large	0	0	N/A	30.360 lb.	0.253

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2019 MCR Safety - All Rights Reserved