

Rigid Couplings

Raintight Compression Type - Malleable Iron

Features

- Raintight and concrete tight
- Compression type couplings
- Threadless
- Suitable for use with UL 6 & UL 6A Rigid Conduit
- For use with steel or aluminum conduit
- EZ slip on labor saving design
- No disassembly required

Applications


- Use to join two lengths of unthreaded Rigid or IMC Conduit

Standard Material

- Malleable iron

Standard Finish

- Zinc plated

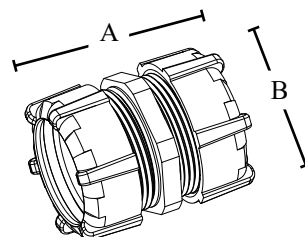

Catalog Number	UPC	Size	Unit Carton	Ship Case	Weight/ Case	Inches	
						A	B
251MRT	02127	1/2"	10	100	32	2.16	1.45
252MRT	02128	3/4"	10	100	40	2.3	1.68
253MRT	02129	1"	5	50	29	2.68	1.93
254MRT	02130	1-1/4"	5	50	42	3.02	2.34
255MRT	02131	1-1/2"	---	12	13	3.16	2.56
256MRT	02133	2"	---	5	9	3.33	3.14
257MRT	02134	2-1/2"	---	5	17	4.38	3.83
258MRT	02135	3"	---	3	12	4.74	4.46
259MRT	02137	3-1/2"	---	2	11	4.86	5.01
260MRT	02141	4"	---	2	12	5.29	5.53