

Rigid Connectors

Raintight Compression Type - Malleable Iron with Insulated Throat

Features

- Raintight and concrete tight
- Compression type connector
- Insulated throat
- Threadless
- Suitable for use with UL 6 & UL 6A Rigid Conduit
- For use with steel or aluminum conduit
- EZ slip on labor saving design
- No disassembly required

Applications


- Use to join unthreaded Rigid or IMC conduit to steel outlet box or metal enclosure

Standard Material

- Malleable iron

Standard Finish

- Zinc plated

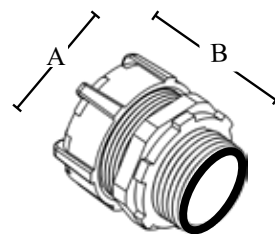

Catalog Number	UPC	Size	Unit Carton	Ship Case	Weight/Case	Inches	
						A	B
261MiRT	02150	1/2"	20	200	45	1.45	1.74
262MiRT	02151	3/4"	10	100	28	1.68	1.87
263MiRT	02155	1"	5	50	34	1.93	2.13
264MiRT	02156	1-1/4"	5	50	34	2.34	2.49
265MiRT	02157	1-1/2"	---	12	11	2.56	2.52
266MiRT	02158	2"	---	12	15	3.14	2.58
267MiRT	02161	2-1/2"	---	5	12	3.83	3.49
268MiRT	02163	3"	---	3	10	4.46	3.69
269MiRT	02165	3-1/2"	---	2	9	5.01	3.73
270MiRT	02167	4"	---	2	10	5.53	3.99