



**MCR  
SAFETY**

# N9690

## Ninja

### Dipped

### Specification Sheet

#### **PRODUCT DESCRIPTION:**

MCR Safety Ninja® gloves are engineered to provide the highest level of innovation. Each of the offerings in the Ninja® series include a unique shell and polymer combination incorporating the latest in hand protection technology. Our Ninja® Glove Line offers the greatest assortment of dexterity, sense of touch, and protection. The Ninja® Ice features a 15 gauge black nylon shell with a 7 gauge acrylic terry interior liner. Black HPT coated palm and fingertips.

#### **FEATURES:**

- Acrylic Terry liner for insulation / warmth.
- HPT repels liquids while providing strong wet or dry grip
- Coating remains soft in temperatures as low as -58 F
- CE score 3232

#### **APPLICATIONS:**

Cold storage applications, Commercial fishing, Frozen food packaging, Agriculture, Construction, Farming, Landscaping, Shipping / receiving, Warehousing



#### **TECHNICAL DATA FOR: N9690L**

<b>Series</b>	Ninja	<b>EN 388 : CE Score - Abrasion</b>	3
<b>Material Group</b>	Strings	<b>EN 388 : CE Score - Cut</b>	2
<b>Product Type</b>	Dipped	<b>EN 388 : CE Score - Tear</b>	3
<b>Glove Size</b>	Large	<b>EN 388 : CE Score - Puncture</b>	2
<b>Gauge</b>	15 / 7 Gauge	<b>ANSI Cut</b>	ANSI Cut A3
<b>Material</b>	Nylon / Acrylic	<b>ANSI Puncture</b>	ANSI Puncture 2
<b>Insulated</b>	Insulated	<b>ANSI Abrasion</b>	ANSI Abrasion 3
<b>Lining</b>	Acrylic	<b>ANSI Contact Heat</b>	Level 2 (Applications less than 284 degrees F)
<b>Made In</b>	Pakistan		




**MCR**  
**SAFETY**

# N9690

## Ninja

### Dipped

#### Specification Sheet

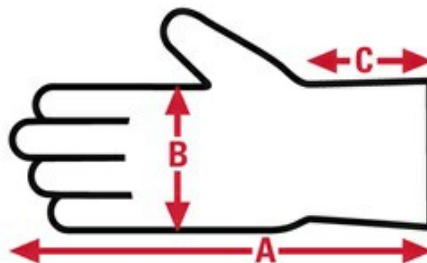

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
N9690S	Small	9.448	3.937	N/A	19.722 lb.	3.287
N9690XL	X - Large	11.024	4.528	N/A	25.092 lb.	4.182
N9690XXL	XX - Large	11.417	4.764	N/A	27.702 lb.	4.617
N9690L	Large	10.228	4.331	N/A	22.158 lb.	3.693
N9690M	Medium	9.843	4.134	N/A	21.552 lb.	3.592

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2019 MCR Safety - All Rights Reserved