




Actual

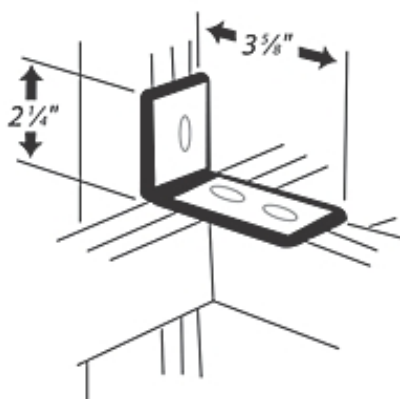

Line Art

Catalog Number: AB204EG
Product ID: 7TAA005290R0015
UPC Number: 61601300749
Status: Active

Fitting, 90 Degree, Height 2-1/4 Inches, Base Length 3-1/2 Inches, Hole Diameter 9/16 Inches, Electro-Galvanized Steel

- Excellent corrosion resistance

North American Specifications (UNSPSC)

UNSPSC	30101504 Steel angles
IGCC	2151 Steel angles
Brand Name	Superstrut
Type	90 degree Angle Fittings
Special Features	Excellent corrosion resistance
Application	For use in metal framing applications
Angle	90 Degree
Length	3-1/2 Inches
Thickness	1/4 Inch
Material Composition	Steel
Finish	SilverGalv

European Specifications (ETIM)

ETIM	EC000483 Coupler for support/profile rail
Suitable for	U-profile
Model	Angle
With screw accessories	N
Material	Steel
Surface protection	Galvanic/electrolytic zinc plated

Packaging

Inner Quantity	1
Outer Quantity	50
Outer Dimensions (inches)	11.9x9.1x4.9
Weight Uom	54.5 lbs. per 100

Documents / Support Tools

Technical Data Sheet US	Available on Website
Technical Data Sheet CA	Available on Website

For further technical assistance, please contact us...

Thomas & Betts - USA
 8155 T&B Blvd.
 Memphis, TN 38125
www.tnb.com

T&B Technical Support
 MS 3B-50
 8155 T&B Blvd.
 Memphis, TN 38125

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com