

Twist-Lock® Devices

15A, 250V, 2 Pole, 3 Wire Grounding

Receptacle

Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

Ordering Information

Description	Device Color	UPC	Catalog Number
Duplex, flush, brown	Brown	783585002378	HBL4550

Listings

Listed to UL 498  
Fed. Spec. W-C-596  
Certified to CSA C22.2 No.42

Specifications

Face	RTP
Base	RTP
Contacts	Brass
Clamp	Brass
Ground Contact	Brass
Terminal Screws	Brass

Performance

Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Terminal Accommodation	#18 AWG - #10 AWG solid or stranded copper wire only.
------------------------	---

Terminal Identification	Terminals identified in accordance with UL 498
-------------------------	--


Environmental

Flammability	HB or better per UL94/CSA 22.2 No.0.17
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

HUBBELL



15A 250V  
NEMA L6-15R  
UL/CSA

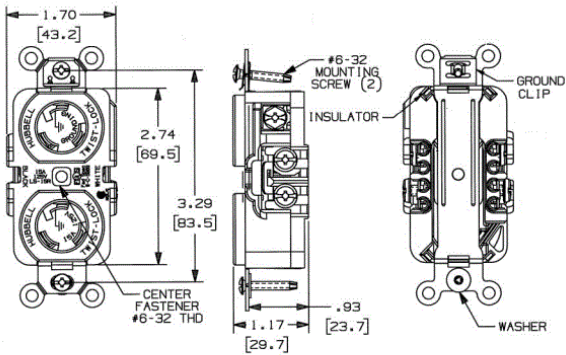

Online Resources

Customer Use Drawing  
eCatalog  
Installation Instructions

Accessories

Plug  
Wallplate or Weatherproof Cover

HBL4570C  
Duplex Opening

