

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Caliber

Outdoor Wall Sconce 3000K

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-W36610 10"	3000K 90	11W	735	560	AL Brushed Aluminum BK Black BZ Bronze WT White

Example: **WS-W36610-AL**

DESCRIPTION

Light projection tuned with precision, Caliber is a discrete cylinder with minimal mounting hardware. Available in a single or double light configuration which can be mounted both vertically and horizontally. The light engine is factory sealed for maximum protection against the harshest elements.

FEATURES


- Discrete cylinder with minimal mounting hardware
- Weather-resistant powder coated finish
- WS-W36614 is Up & down light, WS-W36610 is one direction
- Light engine is factory sealed for maximum protection from the elements
- Driver concealed within the fixture
- 5 year warranty

SPECIFICATIONS


Color Temp:	3000K
Input:	120-277 VAC, 50/60Hz
CRI:	90
Dimming:	ELV: 100 - 10%
Rated Life:	72000 Hours
Mounting:	Can be mounted on wall in all orientations, Can be mounted on wall vertically or horizontally
Standards:	ETL, cETL, IP65 Wet Location Listed
Construction:	Aluminum hardware with lens diffuser



FINISHES

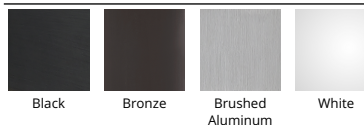

LINE DRAWING

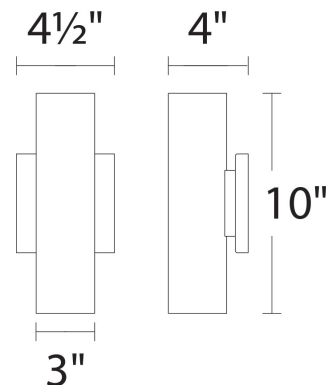

WS-W36610

Fixture Type: _____

Catalog Number: _____

Project: _____

Location: _____

Caliber

Outdoor Wall Sconce 3000K

Model & Size	Color Temp & CRI	Watt	LED Lumens	Delivered Lumens	Finish
WS-W36614 14"	3000K 90	21W	1500	1140	AL Brushed Aluminum BK Black BZ Bronze WT White

Example: **WS-W36614-AL**

DESCRIPTION

Light projection tuned with precision, Caliber is a discrete cylinder with minimal mounting hardware. Available in a single or double light configuration which can be mounted both vertically and horizontally. The light engine is factory sealed for maximum protection against the harshest elements.

FEATURES


- Discrete cylinder with minimal mounting hardware
- Weather-resistant powder coated finish
- WS-W36614 is Up & down light, WS-W36610 is one direction
- Light engine is factory sealed for maximum protection from the elements
- Driver concealed within the fixture
- 5 year warranty

SPECIFICATIONS


Color Temp:	3000K
Input:	120-277 VAC, 50/60Hz
CRI:	90
Dimming:	ELV: 100 - 10%
Rated Life:	72000 Hours
Mounting:	Can be mounted on wall in all orientations, Can be mounted on wall vertically or horizontally
Standards:	ETL, cETL, IP65 Wet Location Listed
Construction:	Aluminum hardware with lens diffuser



FINISHES

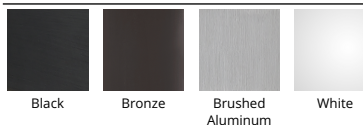

LINE DRAWING

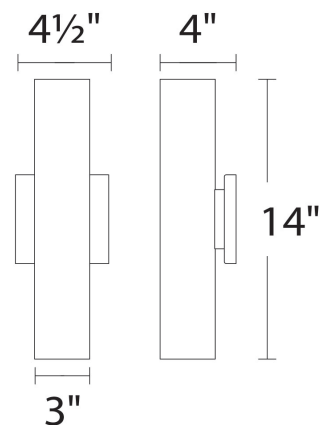

WS-W36614