



Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_

Location: \_\_\_\_\_

Contact/Phone: \_\_\_\_\_

# TRAC-LITES OPEN BACK SPOTLIGHT

**R533 and R534**

## PRODUCT DESCRIPTION

The clean, functional lines of the open back allows maximum adjustability. Open Back Spotlights relamp from back and have floating socket mount and on/off switch. The minimum profile with stylized yoke design is ideal for retail and commercial applications.

**Construction** Die-formed steel.

**Lampholder** Medium base porcelain.

**Aiming** 90° vertical aiming capability and 358° rotation.

**Adapter** Copper alloy contacts provide precise spring action • True, positive electrical ground • On/off switch included • Patented embossed polarity arrows on bottom of adapter • Spring-loaded locking latch with embossed polarity arrows secures trac light to trac • Compatible with both Trac-Lites and Trac-Master Trac • "Pull-up" contact to up position for use on Trac-Master two-circuit trac.


**Labels** UL/CUL listed.

Product specifications subject to change without notice.




## Line Voltage PAR30

Catalog Number	Finish	Lamp
<b>R533WH</b>	White	75W PAR30
<b>R533BL</b>	Black	75W PAR30

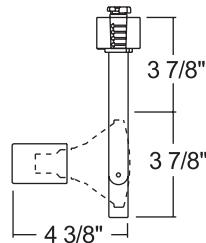

## Line Voltage PAR38

Catalog Number	Finish	Lamp
<b>R534WH</b>	White	120W PAR38
<b>R534BL</b>	Black	120W PAR38

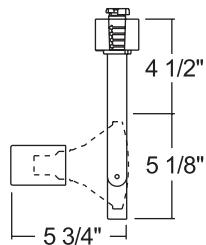

THIS SIDE INTENTIONALLY LEFT BLANK



1300 S. Wolf Road • Des Plaines, IL 60018 • Phone (847) 827-9880 • Fax (847) 827-2925  
220 Chrysler Drive • Brampton, Ontario • Canada L6S 6B6 • Phone (905) 792-7335 • Fax (905) 792-0064  
Visit us at [www.junolightinggroup.com](http://www.junolightinggroup.com) Printed in U.S.A. ©2009 Juno Lighting, LLC.