

CE

LED EMERGENCY EXIT

tradeSELECT®

FEATURES

- LED life-cycle exceeding 10 years
- Red or Green field selectable exits in AC only or emergency
- AC or Emergency models
- Molded-in template for wall mounting, canopy included for ceiling or end mounting
- Dual-voltage 120 or 277V AC input
- Includes long-life Nickel Cadmium (NiCad) or Nickel Metal Hydride (NiMH) for UL recognized 90 minute emergency lighting
- Remote capacity or extended runtime option
- Damp Location Listed 20°C to 30°C (68°F to 86°F)



SPECIFICATIONS

CONSTRUCTION

- The white or black housing is made of high impact UL flame rated thermoplastic with UV protection
- Universal single or double face

INSTALLATION

- Snap together canopy, housing and covers with removable chevrons for quick and easy installation

ELECTRICAL

- The remote capacity option will run 4 CIR/COR single remote lamp-heads or 2 double CIR/COR remote
- Also available with self-test/self-diagnostics to monitor battery/charger failure, battery disconnect and lamp failure

CERTIFICATIONS

- UL924 Listed for Damp Location
- NFPA 101 and NFPA 70
- OSHA
- CEC T20 Compliant

SELF-DIAGNOSTIC FEATURES

- Fault identification for battery, charger, LED integral lamps and remotes
- Self-Testing monthly and annual for 90 minutes
- Manual Testing for 30 second, 15 minutes and 90 minutes

WARRANTY

- 2 year full unit warranty
- See [HLI Standard Warranty](#) for additional information


ORDERING GUIDE

Catalog Number	Description
CARG	White Thermoplastic Exit, Universal Face, Red or Green LED AC Only Exit, Damp Listed 10° to 40°C
CARGB	Black Thermoplastic Exit, Universal Face, Red or Green LED AC Only Exit, Damp Listed 10° to 40°C
CERG	White Thermoplastic Exit, Universal Face, Red or Green LED Emergency Exit, NiCad Battery, CEC T20 Compliant, Damp Listed 10° to 40°C
CERGB	Black Thermoplastic Exit, Universal Face, Red or Green LED Emergency Exit, NiCad Battery, CEC T20 Compliant, Damp Listed 10° to 40°C
CAR	White Thermoplastic Exit, Universal Face, Red LED AC Only Exit
CAG	White Thermoplastic Exit, Universal Face, Green LED AC Only Exit
CARB	Black Thermoplastic Exit, Universal Face, Red LED AC Only Exit
CAGB	Black Thermoplastic Exit, Universal Face, Green LED AC Only Exit
CER	White Thermoplastic Exit, Universal Face, Red LED Emergency Exit, NiCad Battery, CEC T20 Compliant
CERB	Black Thermoplastic Exit, Universal Face, Red LED Emergency Exit, NiCad Battery, CEC T20 Compliant
CEG	White Thermoplastic Exit, Universal Face, Green LED Emergency Exit, NiCad Battery, CEC T20 Compliant
CEGB	Black Thermoplastic Exit, Universal Face, Green LED Emergency Exit, NiCad Battery, CEC T20 Compliant
CERRC	White Thermoplastic Exit, Universal Face, Red LED Emergency Exit, Remote Capacity, NiMH Battery, CEC T20 Compliant
CERRCB	Black Thermoplastic Exit, Universal Face, Red LED Emergency Exit, Remote Capacity, NiMH Battery, CEC T20 Compliant
CEGRC	White Thermoplastic Exit, Universal Face, Green LED Emergency Exit, Remote Capacity, NiMH Battery, CEC T20 Compliant
CERSD	White Thermoplastic Exit, Universal Face, Red LED Emergency Exit, Self-Test/Self-Diagnostics, NiCad Battery, CEC T20 Compliant
CEGSD	White Thermoplastic Exit, Universal Face, Green LED Emergency Exit, Self-Test/Self-Diagnostics, NiCad Battery, CEC T20 Compliant

Accessories (Order Separately)	
WGEL Wireguard	8"H x 20"W x 8" D
CIR Series	Matching LED Indoor Remote Heads
COR Series	Matching LED Outdoor Remote Heads

Note: Remote Capacity Exit will only power Compass Indoor and Outdoor Remote (CIR and COR Series)

DIMENSIONS

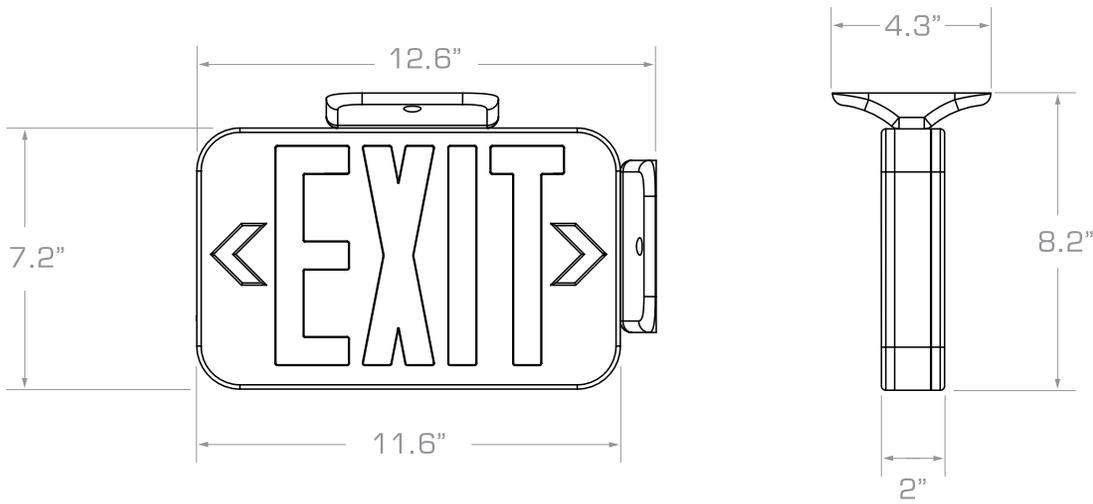

Single Carton Weight	2 lbs.
Master Carton Quantity	6 each

ENERGY CONSUMPTION

	120VAC	277VAC
CARG	2.8W	2.8W
CAR	1.78W	1.88W
CAG	1.52W	1.48W
CERG	3.4W	3.5W
CER	1.78W	1.88 W
CEG	1.49W	1.57 W
CERRC	3.60W	4.14 W
CEGRC	3.28W	3.81 W

ACCESSORIES



CIRS

CIRD

CORD

CORS