

Project:

Type:

Prepared By:

Date:



UPC: 19813748498



Features and Benefits

PREMIUM DECORATIVE BULB REPLACEMENT - Replaces conventional decorative lamps

ENERGY SAVINGS - Save up to 85% on energy

90 CRI - Produces rich and vibrant colors

15,000-HOUR LIFESPAN - Lasts up to 13.7 years at 3 hours per day

DAMP RATED - Suitable for damp locations

ENCLOSED FIXTURE RATED - May be used in both enclosed and open fixtures

FROSTED GLASS - Simulate the appearance of conventional lamps

360° LIGHT OUTPUT - Well suited for decorative lighting applications

DIMMABLE - Compatible with many commonly available dimmers.

Technical Specifications

Product Type	Decorative
Bulb Shape	B11
Finish	Frosted
Wattage	3W
Wattage Equivalency	40W Incandescent
Typical Lumen Output	300
Efficacy	91 lm/W
Color Temperature	2700K Soft White
CRI	90
Base Type	E12
L70 Lifespan	15,000 hours
Operating Temperature	-20°C - 45°C
Dimmable	Yes, down to 10%
Beam Angle	360°
Warranty	3-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	120V
Power Factor	0.7
Flicker	<30%

Listings

ETL Qualified	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2330339
CEC Status	Lawful for sale in California

Light Distribution

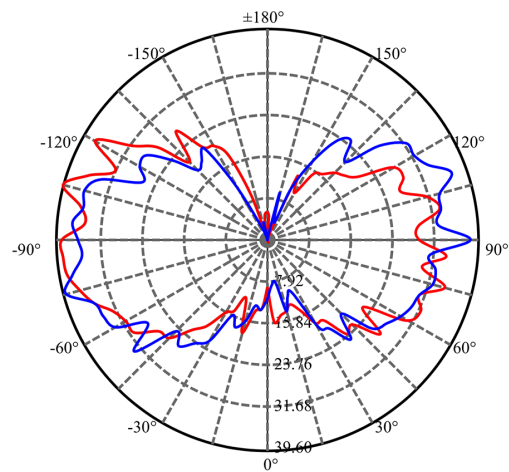

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	12	6.5	4.9	4.7
PALLET	3180	38.4	46.3	39.4

Dimension

