


MONTE CARLO

FAN COLLECTIONS

3DYR56AGP: 56" Dylan - Aged Pewter

Specification Images:

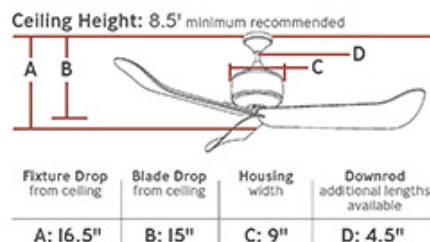

Collection: Dylan

UPC #: 014817564723

Finish: Aged Pewter (AGP)

Blade Finish: Light Grey Weathered Oak

Blade Finish 2: Undefined

Dimensions:

Diameter:	56"
Weight:	17.2 lbs.
Reverse Switch:	Remote Controlled
Rev. Switch Location:	Remote Transmitter
Motor Size:	188.0 X 25.0
Diameter of Housing:	11.3
Lead Wire Length:	78 inches
Remote Included:	Hand Remote
Location of Receiver:	Canopy
Remote Group(s):	

Features:

- Includes a green, energy-efficient DC motor
- Remote included for easy operation

Material List:

Safety Listing:

Safety Listed for Wet Locations

Instruction Sheets:

English (3DYR56XX-ETL-ENG)
French (3DYR56XX-ETL-CF)

Blade Details:

Blade Group	Diameter	Included	RPM Hi	CFM Hi	Watts Hi	Amps Hi	RPM Med	CFM Med	Watts Med	Amps Med	RPM Low	CFM Low	Watts Low	Amps Low
	56	Yes	118.0	8605.92	40.54						74.0	3480.81	3.65	

Mounting Options:

Mounting Type	Included	Item	Downrod Length	Downrod Diameter	Overall Height	Blade to Ceiling	Min. Ceiling Height	Canopy Style	Canopy Diameter
Downrod (Included)	yes		4.5	0.5	16.5	13.5	8.13	Downrod	5.25

Shipping Information:

Package Type	Product #	Quantity	UPC	Length	Width	Height	Cube	Weight	Frt. Class	UPS Ship
--------------	-----------	----------	-----	--------	-------	--------	------	--------	------------	----------

Monte Carlo reserves the right to revise the design of components of any product due to parts availability or change in safety listing standards without assuming any obligation or liability to modify any products previously manufactured and without notice. This literature depicts a product design that is the sole and exclusive property of Monte Carlo. In compliance with U.S copyright and patent requirements, notification is hereby presented in this form that this literature, or the product it depicts, is not to be copied, altered or used in any manner without the express written consent of, or contrary to the best interests of Monte Carlo.

Individual	3DYR56AGP	1	014817564723	30	13.75	11.75	2.805	22.1	110	Yes
Master Pack	3DYR56AGP	2	10014817564720							
NJ Pallet		24		48	40	73.5	81.667	530.4		No
NV Pallet		24		48	40	73.5	81.667	530.4		No