

Project:

Type:

Prepared By:

Date:



UPC: 19813750545



Features and Benefits

SMALL REFLECTOR REPLACEMENT - Replaces conventional small-reflector lamps

ENERGY SAVINGS - Save up to 85% on energy

25,000-HOUR LIFESPAN - Long-life product

DAMP RATED - Suitable for damp locations

DIMMABLE - Compatible with most common dimmer models

80 CRI - Ideal for general lighting applications

Technical Specifications

Product Type	Small-Reflector
Bulb Shape	GU10
Wattage	5W
Wattage Equivalency	50W Halogen
Typical Lumen Output	400
Efficacy	73 lm/W
Color Temperature	4000K Cool White
CRI	80
Base Type	GU10
L70 Lifespan	25,000 hours
Operating Temperature	-20°C - 40°C
Dimmable	Yes, down to 20%
Beam Angle	35°
Warranty	3-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	120V
Power Factor	0.7
Flicker	<30%

Listings

UL Listed	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2329473
CEC Status	Not lawful for sale in California

Light Distribution

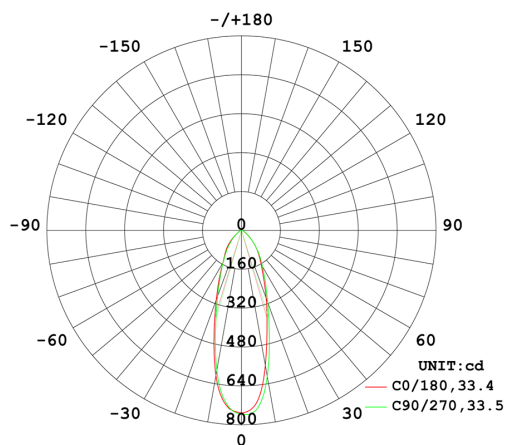

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	10	10.4	4.3	2.8
PALLET	3120	47.6	40	13.8

Dimension

