

Project:

Type:

Prepared By:

Date:



UPC: 19813750200



Features and Benefits

SMALL REFLECTOR REPLACEMENT - Replaces conventional small-reflector lamps

ENERGY SAVINGS - Save up to 85% on energy

25,000-HOUR LIFESPAN - Long-life product

DAMP RATED - Suitable for damp locations

DIMMABLE - Compatible with most common dimmer models

90 CRI - Produces rich and vibrant colors

Technical Specifications

Product Type	Small-Reflector
Bulb Shape	MR16
Wattage	6W
Wattage Equivalency	35W Halogen
Typical Lumen Output	420
Efficacy	65 lm/W
Color Temperature	2700K Soft White
CRI	90
Base Type	GU5.3
L70 Lifespan	25,000 hours
Operating Temperature	-20°C - 40°C
Dimmable	Yes, down to 10%
Beam Angle	35°
Warranty	4-Year, No-Compromise Warranty
For Use in Emergency Fixtures	No
For Use Outdoors in Open Fixtures	No


Electrical Characteristics

Input Voltage	12V
Power Factor	0.9
Flicker	<30%

Listings

UL Listed	Yes
ENERGY STAR V2.0	This product is ENERGY STAR® Version 2.0 Certified
Energy Star ID	2329456
CEC Status	Not lawful for sale in California

Light Distribution

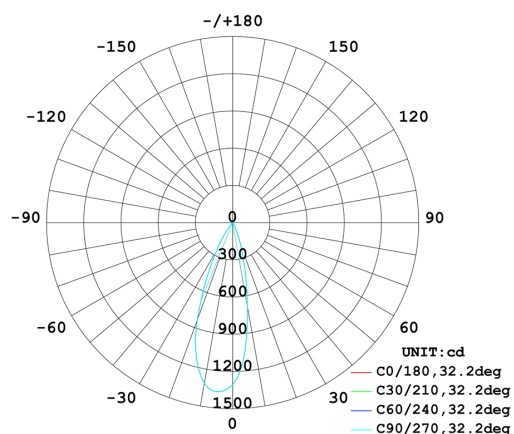

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	12	7.7	5.7	2.6
PALLET	4536	47.8	40	10.2

Dimension

