

Project:

Type:

Prepared By:

Date:



UPC: 019813748399



Features and Benefits

REPLACE conventional halogen and incandescent bulbs

ENERGY SAVINGS - Save up to 85% on energy

DAMP RATED - Suitable for damp locations

15,000-HOUR LIFESPAN - Last up to 13.7 years at 3 hours per day

OPEN FIXTURE RATED - May be used in open fixtures

SHATTERPROOF - Plastic lamps for rugged applications

80 CRI - Ideal for general lighting applications

DIMMABLE - Compatible with most common dimmer models

Technical Specifications

Technical Specifications

Product Type:

A-Line

Bulb Shape:

A19

Wattage:

15.5W

Wattage Equivalency:

100W Incandescent

Typical Lumen Output:

1680

Efficacy:

97 lm/W

Color Temperature:

4000K Cool White

CRI:

80

Base Type:

GU24

L70 Lifespan:

15,000 hours

Operating Temperature:

-20°C - 45°C

Dimmable:

Yes, down to 10%

Beam Angle:

230°

Warranty:

3-Year, No-Compromise Warranty

For Use in Emergency Fixtures:

No

For Use Outdoors in Open Fixtures:

No

Electrical Characteristics

Input Voltage:

120V

Technical Specifications (continued)

Electrical Characteristics

Power Factor:

 ≥ 0.7

Operating Frequency:

60 Hz

Listings

ENERGY STAR V2.0:

This product is ENERGY STAR® Version 2.0 Certified

Energy Star ID:

2329589

CEC Status:

Not lawful for sale in California


Other

:

Case and Pallet Dimensions

	QTY	LENGTH	WIDTH	HEIGHT
CASE	12	15.4	5.2	4.9
PALLET	2268	47.2	39.4	45.7

Dimension

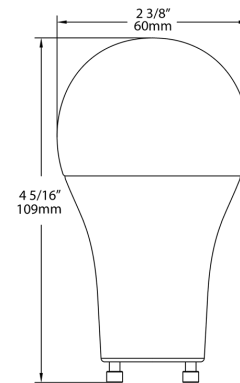

Light Distribution

