




RIGID-IMC FITTINGS

MALLEABLE IRON INSULATED BUSHINGS

[Download
Specification Sheet
\(\[https://www.sepco-
usa.com/wp-
content/uploads/2017/03/page_060.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page_060.pdf\)\)](#)



[Print](#) 

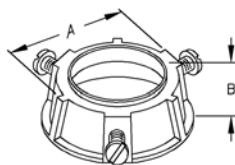

1206

Trade Size	1/2"
Dim A	184
Dim B	0.50
Unit Pack	100
Master Pack	1000
Lbs. / 100 Pcs.	6

UPC

12061

Competitor Part
Number

**U50I, 361,
H1031, MCBI-50,
IBC-50, 1132,
1132, BI-901,
1222, 311M**

APPLICATION

Used with a locknut to terminate threaded/ threadless rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface. Thermoplastic liner prevents damage to wire insulation. Liner rated at 150°C.

FEATURES

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

STANDARD**MATERIALS**

Malleable Iron

STANDARD**FINISH**

Zinc plated

UL LISTED

E198258



