




RIGID-IMC FITTINGS

MALLEABLE IRON INSULATED BUSHINGS

[Download
Specification Sheet
\(\[https://www.sepco-
usa.com/wp-
content/uploads/2017/03/page_060.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page_060.pdf\)\)](#)



[Print](#) 

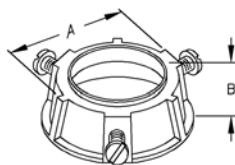

1207

Trade Size	3/4"
Dim A	1.44
Dim B	0.56
Unit Pack	100
Master Pack	500
Lbs. / 100 Pcs.	9

UPC

12071

Competitor Part
Number

**U75I, 362,
H1032, MCBI-75,
IBC-75, 1133,
1133, BI-902,
1223, 312M**

APPLICATION

Used with a locknut to terminate threaded/ threadless rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface. Thermoplastic liner prevents damage to wire insulation. Liner rated at 150°C.

FEATURES

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

STANDARD**MATERIALS**

Malleable Iron

STANDARD**FINISH**

Zinc plated

UL LISTED

E198258



