




## RIGID-IMC FITTINGS

### MALLEABLE IRON INSULATED BUSHINGS

[Download  
Specification Sheet  
\(\[https://www.sepco-  
usa.com/wp-  
content/uploads/2017/03/page\\\_060.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page\_060.pdf\)\)](#)



[Print](#) 

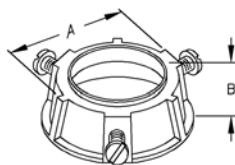

### 1208

Trade Size	<b>1"</b>
Dim A	<b>1.75</b>
Dim B	<b>0.63</b>
Unit Pack	<b>50</b>
Master Pack	<b>500</b>
Lbs. / 100 Pcs.	<b>13</b>

UPC

***12081***

Competitor Part  
Number

***U100I, 363,  
H1033, MCBI-  
100, IBC-100,  
1134, 1134, BI-  
903, 1224, 313M***

## APPLICATION

Used with a locknut to terminate threaded/ threadless rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface. Thermoplastic liner prevents damage to wire insulation. Liner rated at 150°C.

## FEATURES

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

## STANDARD

### MATERIALS

Malleable Iron

## STANDARD

### FINISH

Zinc plated

## UL LISTED

E198258



