




RIGID-IMC FITTINGS

MALLEABLE IRON INSULATED BUSHINGS

[Download
Specification Sheet
\(\[https://www.sepco-
usa.com/wp-
content/uploads/2017/03/page_060.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page_060.pdf\)\)](#)



[Print](#)

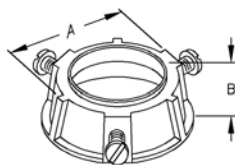

1209

Trade Size	1-1/4"
Dim A	2.13
Dim B	0.75
Unit Pack	25
Master Pack	250
Lbs. / 100 Pcs.	17

UPC

12091

Competitor Part
Number

***U125I, 364,
H1034, MCBI-
125, IBC-125,
1135, 1135, BI-
904, 1225, 314M***

APPLICATION

Used with a locknut to terminate threaded/ threadless rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface. Thermoplastic liner prevents damage to wire insulation. Liner rated at 150°C.

FEATURES

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

STANDARD**MATERIALS**

Malleable Iron

STANDARD**FINISH**

Zinc plated

UL LISTED

E198258



