




RIGID-IMC FITTINGS

MALLEABLE IRON THREADLESS INSULATED GROUNDING BUSHINGS

[Download
Specification Sheet
\(\[https://www.sepco-usa.com/wp-content/uploads/2017/03/page_057.pdf\]\(https://www.sepco-usa.com/wp-content/uploads/2017/03/page_057.pdf\)\)](#)



[Print](#)

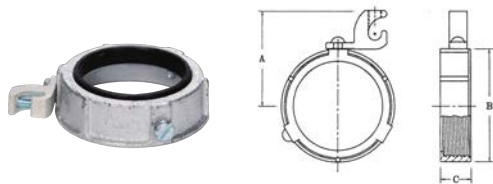

21BI4LSS

Trade Size	3/4"
GROUNDING LUG CAPACITY	#14-#4
Dim A	1.44
Dim B	0.64
Dim C	0.64

Unit Pack	50
Master Pack	500
Lbs. / 100 Pcs.	11
UPC	12701
Competitor Part Number	IB-75SL-4, HGLS2, IBC-75LS- 4AC, 332MSS

APPLICATION

Used with a locknut to terminate threadless rigid and IMC conduit to a box or enclosure and to provide a smooth pulling surface.

Thermoplastic liner prevents damage to wire insulation.

Liner rated at 150°C.

FEATURES

The plastic liner won't chip, crack, swell or shrink. It resists corrosion, chemicals, and temperature extremes.

Set-screw provided with each fitting

locks bushing in any desired position.

UL Listed for use with Copper or Aluminum Grounding Conductors.

STANDARD MATERIALS

Malleable Iron/Open side tin plated aluminum lug.

STANDARD FINISH

Zinc plated

UL LISTED

E93683

