




PRODUCT DESCRIPTION:

Portsmouth is a traditional, early American style collection from Maxim Lighting International in Oil Rubbed Bronze finish with Seedy glass.

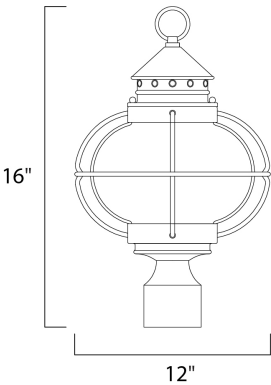

MEASUREMENTS:


<u>Length</u>	<u>Width</u>	<u>Height</u>
12.00"	12.00"	16.00"
<u>Hanging Weight</u>		
3.31 lb		

LAMPING:

3.00 of Bulbs	
40W	2,016 RATED LUMENS
120 TOTAL WATTAGE	
	INPUT VOLTAGE: 120

DIMMABLE : Standard Dimmer

FINISHES OPTION:

Oil Rubbed Bronze Ol 

GLASS:

Seedy CD

MATERIAL:

Aluminum

CERTIFICATION:

Wet Location



ADDITIONAL:

CA (NOT INCLUDED)
RATED LIFE 1500 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746
EASTERN DISTRIBUTION CENTER
4200 SHIRLEY DR. | ATLANTA, GA 30336
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com