

LED A19-A21

8.8A19/PER/950/CL/G/E26/DIM 1FB T20

Philips A19/A21 LED lamps are the smart alternative to standard incandescent. The unique lamp design provides omni-directional light with excellent dimming performance.

Product data

General Information	
Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	8.8-60W

Light Technical	
Color Code	950 [CCT of 5000K]
Initial lumen (Nom)	800 lm
Color Designation	Daylight
Correlated Color Temperature (Nom)	5000 K
Luminous Efficacy (rated) (Nom)	90.00 lm/W
Color Consistency	<4
Color Rendering Index (Nom)	90
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	8.8 W
Lamp Current (Nom)	105 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V

Temperature	
T-Case Maximum (Nom)	60 °C


Controls and Dimming	
Dimmable	Yes

Mechanical and Housing	
Bulb Finish	Clear

Product Data	
Order product name	8.8A19/PER/950/CL/G/E26/DIM 1FB T20
EAN/UPC - Product	046677549237
Order code	549238
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929002207904
Net Weight (Piece)	0.030 kg

LED A19-A21


Dimensional drawing

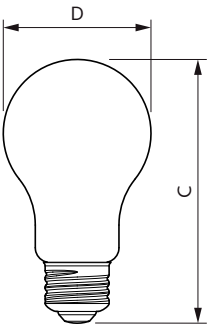


Bulb A19 120V 8.0-60W 800lm 5000K E26DCL

Product	D	C
8.8A19/PER/950/CL/G/E26/DIM 1FB T20	60 mm	108 mm


Photometric data

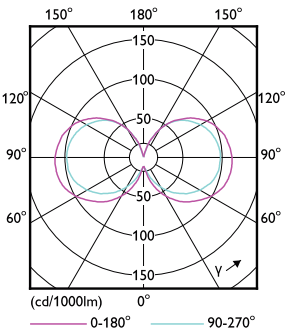

LEDbulb E12 E26 BA11 B11 927 CL-LDD

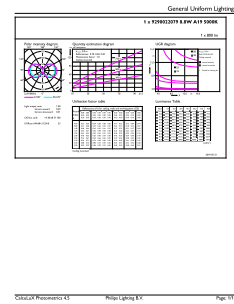

LEDbulb 60W E26 A19 950 CL

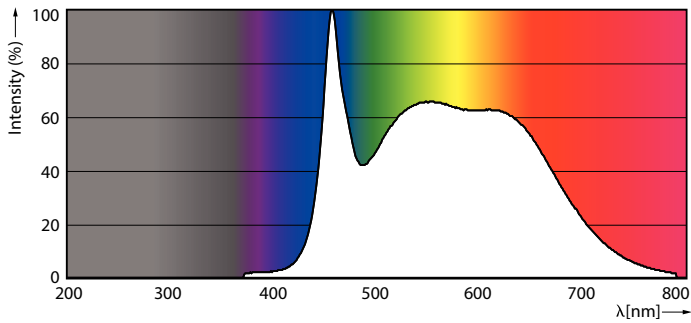

LEDbulb 40,60W E26 950

LED A19-A21

Lifetime



15K LED



15K LMP

