

GL100BPGO



Unbreakable Polycarbonate threaded globes to fit RAB and other standard size Vaporproof fixtures. Lamp base up only.

Color: Opal

Weight: 1.6 lbs

Project:

Type:

Prepared By:

Date:

Technical Specifications

Listings

UL Listing:

Suitable for wet locations when used with Vaporproof fixtures. Suitable for dry, damp or wet locations when used as replacement globes for listed fixtures. Fixtures must be installed with lamp base up when outdoors.

Construction

Polycarbonate Globe:

Clear thermal shock resistant polycarbonate standard.

Material:

Poly.

Electrical

Maximum Wattage:


75 watts.

Other

Buy American Act Compliance:

RAB values USA manufacturing! Upon request, RAB may be able to manufacture this product to be compliant with the Buy American Act (BAA). Please contact customer service to request a quote for the product to be made BAA compliant.

Dimensions

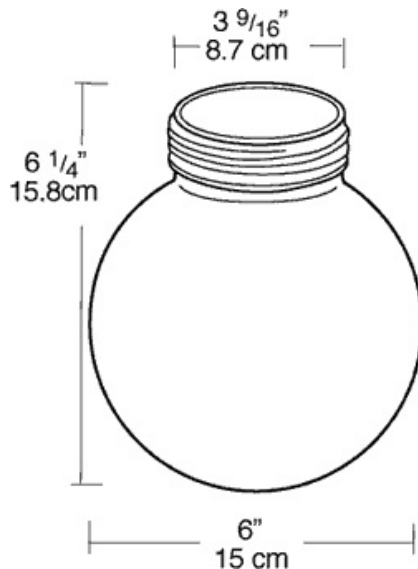

Features

Unbreakable polycarbonate globe in two sizes and six colors

Industry standard 3 5/32" or 4 5/32" threads

Colors available for signaling or decorative applications