




< Cable Ladders

## CABLE LADDER, 119", 12"W

**CLB-10**

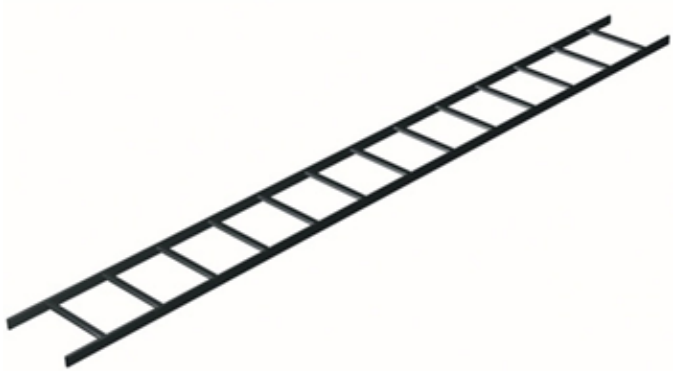

Strong welded sections, individually boxed

MSRP

\$169.00

Qty

1

ADD TO MATERIALS

Share this product



SPECIFICATIONS



GENERAL INFO

Finish: Black Powder Coat  
Quantity: 1  
Component Type: Cable Ladders  
Style: 119" long straight ladder section

DIMENSIONS

Height (US): 1.5  
Length (US): 119  
Width (US): 12

LISTING AGENCIES/THIRD PARTY CERTIFICATIONS

RoHS: Yes  
Greenguard: Yes  
UL Listing No: E239321

TECHNICAL INFORMATION

Material: Steel

ECO-BENEFIT INFORMATION

RoHS Compliant



Single piece 10’ long straight cable ladder sections shall be Middle Atlantic Products model # CLB-10. Ladder sections shall be 119” long x 12” wide x 1.5” thick, rungs shall be 1” x .5” x 11.25” tube. Ladder section shall have 10 rungs on 12” centers. Ladder shall be constructed of ASTM A570 structural steel finished in a durable black powder coat. Each CLB series ladder section shall be individually boxed with handles. CLB Series cable ladder shall have up to 187 lb. weight capacity per foot based on a 4 ft. support span. Cable ladder shall be classified by UL in the US and Canada. Cable ladder shall be GREENGUARD Gold Certified. Cable ladder shall comply with the requirements of RoHS EU Directive 2002/95/EC. Cable ladder shall be manufactured by an ISO 9001 and ISO 14001 Registered Company. Cable ladder shall be warrantied to be free from defects in material and workmanship under normal use and conditions for the lifetime of the product.

RESOURCES



3D CAD



3-Part CSI MasterFormat Spec



A&E Technical Specifications



CL Series Spec  
PDF 2.5mb

CAD Drawings



CAD Technical Specification Drawings



Instruction Sheet



INST,CL-GK CABLE LADDER BONDING KIT  
PDF 835.21kb

Revit Models



Visio Blocks



FEATURES & BENEFITS



COMPATIBLE PRODUCTS

