


Group D

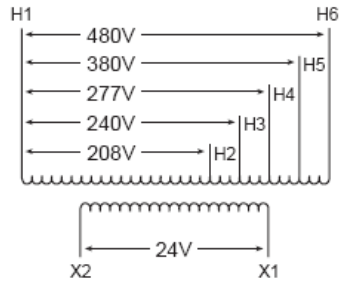

Type No.

VA	CATALOG NUMBER	VOLTAGE		WIRING DIAGRAM	WEIGHT	PHASE	FREQ.
		HIGH	LOW				
250	TB-81325	208/240/277 380/480	24		11 Lbs	1 ϕ	50/60 ..

TYPICAL PERFORMANCE DATA

Winding Temp:	80°C
Insulation:	130°C
Windings:	CU

Standard	UL/CSA	Markings:	
----------	--------	-----------	--

Industrial Control Transformer

Typical Efficiency:	
Full Load Losses	
No Load Losses	

A	B	C	D	E	F			
5.24	4.65	4.15	4.06	3.25	.22x.50			

						A	PRINTS TO	CONTROL 7
--	--	--	--	--	--	----------	-----------	------------------

Date: Feb 21, 2011